

64337 B 45-15

Halogen lamps with reflector, current-controlled, 45...48 W



Product benefits

- Reduced operation and maintenance costs due to long life time
- Instant and constant light output over the lamp life
- Flicker-free operation
- Mercury-free

Product features

- Dimmable
- Available with connector combinations A, B, C/Z on request
- Infrared radiation output that provides light in the worst of conditions



Product datasheet

Technical data

Electrical data


Nominal wattage	45.00 W
Nominal current	6.60 A

Photometrical data

Axial luminous intensity	21000 cd
Luminous intensity	19000 cd ¹⁾

¹⁾ Minimum

Dimensions & weight

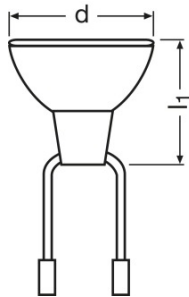

Product line drawing

Diameter	50.4 mm
Length with base excl. base pins/connection	45.00 mm
Length	45.0 mm

Lifespan

Lifespan	1500 h
----------	--------

Country specific categorizations

Order reference	64337 B 45W-15
-----------------	----------------

Safety advice

To prevent personal injury or damage to property, halogen lamps may only be operated in suitable luminaires designed with suitable mechanisms (protective shields, grids, etc.) to ensure that in the event of a lamp bursting no parts/shards can escape and that during operation no ultraviolet radiation can escape. There must also be a warning sign to indicate that the lamps give off high levels of heat. Detailed information is available on request.

References / Links

For more information on airfield lamps see the brochure:
"The reliable guiding stars - Effective solutions for airfield lighting: Tungsten halogen lamps and LED light sources".

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.