

Euromas Polymas

Enclosure



PK 102
Order no.: 38102000

* = Available on request.

Characteristics

Colour of enclosure group
silver-grey

Protection class
IP 65

Enclosure Material
PA 6-GB 30, seal made of CR; for details see Technical Information


Scope of delivery
Lid and base, lid screws made of V2A

Note
G = Model with crystal clear lid.

Dimensions

Dimensions
98 x 64 x 34 mm

Product drawing

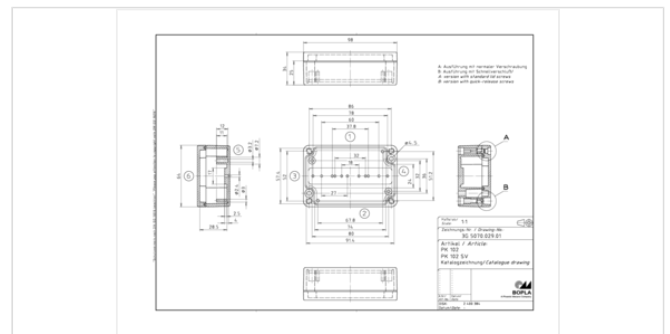

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

Technical documentation / Downloads

Technical drawings

3D product data in STEP format: 38102000 PK-102.stp (565.2 KB)
Product drawing in PDF format: 38102000 PK-102.pdf (48.6 KB)
Product drawing in DXF format: 38102000 PK-102.dxf (561.7 KB)
Drawing for mechanical processing: 38102000 PK-102-G.dxf (617.6 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

Product information

Euromas Polymas GB.pdf (306.5 KB)