


Datasheet


Quick acting F HBC min fuse,6.3A 5x20mm

RS Stock number [537-1319](#)

Dimensions - mm Drawing Not to Scale

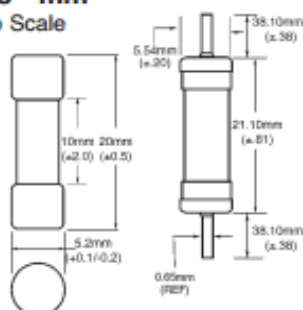

Time -Current Curve

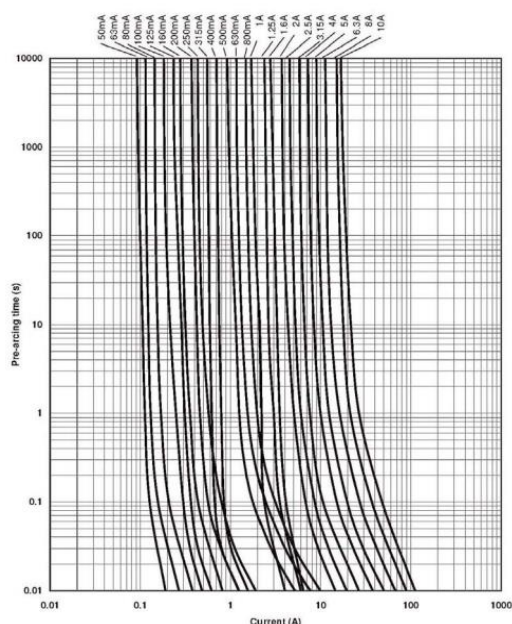

Description

- Fast-acting high breaking capacity
- Optional axial leads available
- 5x20mm physical size
- Ceramic tube with silver-plated (50A-400A) and nickel plated 500A-10A) end caps
- Designed to IEC 60127-2
- RoHS certified

Electrical Characteristics

I_n	$1.5 I_n$ min	$2.1 I_n$ max	$2.75 I_n$ min	$4 I_n$ max	$10 I_n$ max
50mA-4A	60 min	30 min	10 ms	2 sec	3 ms
5A-6.3A	60 min	30 min	10 ms	3 sec	3 ms
8A-10A	30 min	30 min	40 ms	20 sec	10 ms