



# ATH-M40x


The high-performance ATH-M40x professional headphones are tuned flat for incredibly accurate audio monitoring across an extended frequency range. Your studio experience is enhanced with superior sound isolation and swiveling earcups for convenient one-ear monitoring. Engineered with pro-grade materials and robust construction, the M40x excels in professional studio tracking and mixing, as well as DJ monitoring.

- Cutting-edge engineering and robust construction
- 40 mm drivers with rare earth magnets and copper-clad aluminum wire voice coils
- Tuned flat for incredibly accurate sound monitoring across the entire frequency range
- Circumaural design contours around the ears for excellent sound isolation in loud environments
- 90° swiveling earcups for easy, one-ear monitoring
- Professional-grade earpad and headband material delivers more durability and comfort
- Detachable cable (2 cables included)

## Included Accessories



Driver	40 mm
Magnet	Neodymium
Voice Coil	CCAW (Copper-clad aluminum wire)
Frequency Response	15 – 24,000 Hz
Maximum Input Power	1,600 mW at 1 kHz
Sensitivity	98 dB
Impedance	35 ohms
Weight	240 g (8.5 oz) without cable and connector

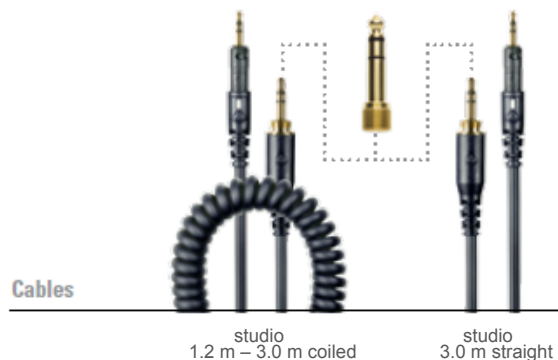

Cables

studio  
1.2 m – 3.0 m coiled

studio  
3.0 m straight