

**W-Series  
WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com



**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	WDK 2.5N
Order No.	<a href="#">1041600000</a>
Version	Double-tier terminal, Screw connection, 2.5 mm <sup>2</sup> , 800 V, 24 A, Dark Beige
GTIN (EAN)	4032248138807
Qty.	100 pc(s).

**W-Series**  
**WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Technical data****Dimensions and weights**

Width	5.1 mm	Width (inches)	0.201 inch
Height	61 mm	Height (inches)	2.402 inch
Depth	62 mm	Depth (inches)	2.441 inch
Depth including DIN rail	62.45 mm	Net weight	11.057 g

**Temperatures**

Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C
----------------------------------	--------	----------------------------------	--------

**Material data**

Material	Wemid	Colour	Dark Beige
UL 94 flammability rating	V-0		

**Rating data IECEx/ATEX**

Certificate No. (ATEX)	KEMA00ATEX2061U	Certificate No. (IECEX)	IECEXULDO5.0008U
Max. voltage (ATEX)	550 V	Current (ATEX)	21 A
Wire cross section max. (ATEX)	2.5 mm <sup>2</sup>	Max. voltage (IECEX)	550 V
Current (IECEX)	20 A	Wire cross section max. (IECEX)	2.5 mm <sup>2</sup>
Voltage, cross-connection		Operating temperature range	For operating temperature range see EC Design Test Certificate / IEC Ex-Certificate of Conformity
	CrossConnectionGuide.pdf		
Marking EN 60079-7	Ex e II	Ex 2014/34/EU label	II 2 G D

**System specifications**

Version	Screw connection, for plug-in cross-connector, One end without connector	End cover plate required	Yes
Number of potentials	2	Number of levels	2
No. of clamping points per level	2	Number of potentials per tier	1
Levels cross-connected internally	No	PE connection	No
Mounting rail	TS 35	N-function	No
PE function	No	PEN function	No

**2 clampable conductors (H05V/H07V) with equal cross-section (rated connection)**

Wire connection cross section, finely stranded, two clampable wires, min.	0.5 mm <sup>2</sup>	Wire cross-section, finely stranded, two clampable wires, max.	1.5 mm <sup>2</sup>
Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, 2 clampable wires, min.	0.5 mm <sup>2</sup>	Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, 2 clampable wires, max.	1.5 mm <sup>2</sup>

**Additional technical data**

Explosion-tested version	Yes	Number of similar terminals	1
Open sides	right	Type of mounting	Snap-on

**W-Series**  
**WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Technical data****CSA rating data**

Certificate No. (CSA)	200039-1057876	Current size C (CSA)	20 A
Current size D (CSA)	5 A	Voltage size C (CSA)	300 V
Voltage size D (CSA)	600 V	Wire cross section max. (CSA)	12 AWG
Wire cross section min. (CSA)	26 AWG		

**Conductors for clamping (rated connection)**

Blade size	0.6 x 3.5 mm	Clamping range, rated connection, max.	4 mm <sup>2</sup>
Clamping range, rated connection, min.	0.05 mm <sup>2</sup>	Clamping screw	M 2.5
Connection direction	on side	Cross-section for connected conductor, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, min.	2.5 mm <sup>2</sup>
Gauge to IEC 60947-1	A3	Number of connections	4
Stripping length	8 mm	Tightening torque, max.	0.6 Nm
Tightening torque, min.	0.4 Nm	Torque level with DMS electric screwdriver	1
Type of connection	Screw connection	Wire connection cross section AWG, max.	AWG 12
Wire connection cross section AWG, min.	AWG 30	Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, max.	2.5 mm <sup>2</sup>
Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, min.	0.5 mm <sup>2</sup>	Wire connection cross section, finely stranded, max.	4 mm <sup>2</sup>
Wire connection cross section, solid core max. rated connection	4 mm <sup>2</sup>	Wire connection cross section, solid core, min. rated connection	0.5 mm <sup>2</sup>
Wire connection cross section, stranded, rated connection, max.	4 mm <sup>2</sup>	Wire connection cross section, stranded, rated connection, min.	1.5 mm <sup>2</sup>
Wire connection cross-section, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, max.	2.5 mm <sup>2</sup>	Wire connection cross-section, finely stranded, min.	0.5 mm <sup>2</sup>

**Rating data**

Rated cross-section	2.5 mm <sup>2</sup>	Rated voltage	800 V
Rated current	24 A	Current at maximum wires	28 A
Standards	IEC 60947-7-1	Volume resistance according to IEC 60947-7-x	2.66 mΩ
Rated impulse withstand voltage	8 kV	Pollution severity	3

**Classifications**

ETIM 3.0	EC000897	ETIM 4.0	EC000897
ETIM 5.0	EC000897	ETIM 6.0	EC000897
UNSPSC	30-21-18-11	eClass 5.1	27-14-11-20
eClass 6.2	27-14-11-20	eClass 7.1	27-14-11-20
eClass 8.1	27-14-11-20	eClass 9.0	27-14-11-20
eClass 9.1	27-14-11-20		

**Product information**

Descriptive text technical data	Rated voltage is reduced to 400 V when using the ZQV 2.5N cross-connector.
Descriptive text accessories	Cross-connections, see section "W series accessories".

**Data sheet****W-Series  
WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Technical data****Approvals**

Approvals



ROHS

Conform

**Downloads**

 
Certificate of conformity	<a href="#">CFAT_WDK 2.5N.pdf</a>
Engineering data	<a href="#">EPLAN, WSCAD, Zuken E3.S</a>
Declaration of Conformity	<a href="#">DE_PT1001_20160418_709_ISSUE01.pdf</a>

**Data sheet**

**W-Series**  
**WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



**W-Series  
WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

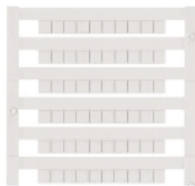
**Accessories**
**Shielding bus**

**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
LS 2.8 WDU2.5-10	<a href="#">1056400000</a>	W-Series, Shield bus	4008190036454	100 pc(s).

**Blank**


The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/5 MC NE WS	<a href="#">1609801044</a>	Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, White	4008190397111	1,000 pc(s).

## W-Series WDK 2.5N

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

## Accessories

### End plates



#### **Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

#### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WAP	<a href="#">1084000000</a>	W-Series, End plate	4032248127351	20 pc(s).
WDK2.5/4 N				
WAP	<a href="#">1084080000</a>	W-Series, End plate	4032248127337	20 pc(s).
WDK2.5/4 N				
BL				

### Partition plates



#### **Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

#### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WTW EN	<a href="#">1058800000</a>	W-Series, Separation plate	4008190140175	20 pc(s).

### End brackets



#### **Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

#### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WEW 35/2	<a href="#">1061200000</a>	W-Series, End bracket	4008190030230	100 pc(s).

**W-Series  
WDK 2.5N**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

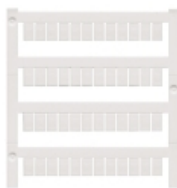
**Accessories**
**ZQV 2.5N**

**Spring connection with tension clamp Technology**

Tension clamp technology is a universal contact system for all common conductor connection types. Its fantastic level of flexibility makes the tension clamp a profitable alternative connection.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
ZQV 2.5N/2 GE	<a href="#">1693800000</a>	Z-series, Cross-connector, 24 A	4008190883621	60 pc(s).
ZQV 2.5N/4 GE	<a href="#">1693820000</a>	Z-series, Cross-connector, 24 A	4008190883652	60 pc(s).
ZQV 2.5N/3 GE	<a href="#">1693810000</a>	Z-series, Cross-connector, 24 A	4008190883645	60 pc(s).
ZQV 2.5N/20 GE	<a href="#">1909000000</a>	Z-series, Cross-connector, 24 A	4032248535613	20 pc(s).
ZQV 2.5N/10 GE	<a href="#">1693880000</a>	Z-series, Cross-connector, 24 A	4008190883720	20 pc(s).

**Blank**


WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with laser printer, PrintJet ADVANCED, plotter or MC-Mobilo is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
WS 8/5 MC NE WS	<a href="#">1640740000</a>	WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, Allen-Bradley, White	4008190279103	720 pc(s).

# Addresses worldwide

Let's connect.

## AE United Arab Emirates

Weidmüller Middle East FZE  
Warehouse Q3-79  
SAIF-Zone  
P.O. BOX 8591  
Sharjah  
Telephone number +971  
65572723  
Fax number +971 65572724  
wme.info@weidmueller.com

## AF Afghanistan

Representative Office

AF 11050 Beograd  
Telephone number +381 11  
2885 274  
Fax number +381 11 2885  
274  
zoran.rabrenovic@  
weidmueller.com

## AO Angola

Please contact  
Phambili Interface  
South Africa

## AR Argentina

CPI SA  
Bauness 2660  
C1431DOF Buenos Aires  
Telephone number +54 11  
4523 8008  
Fax number +54 11 4522  
0546  
info@cpi.com.ar  
www.cpi.com.ar

## AT Austria

Weidmüller GmbH  
IZ NOE Süd, Str. 2b, Obj. M59,  
2355 Wiener Neudorf  
Telephone number +43 2236  
67080  
Fax number +43 2236  
6708-899  
office.at@weidmueller.com  
www.weidmueller.com

## AU Australia

Weidmüller Pty. Ltd.  
PO BOX 6944  
Huntingwood 2148  
Huntingwood Drive 43  
Huntingwood NSW 2148  
Telephone number +61 2  
9671 9999  
Fax number +61 2 9671  
9911  
info@weidmuller.com.au  
www.weidmuller.com.au

## AZ Azerbaijan

Representative Office  
Weidmüller Interface  
Demirchi Tower, 4th floor  
37, Khojali ave.  
AZ 1025 Baku  
Telephone number +994 12  
488 80 36  
Fax number +994 12 488  
80 37  
aliyar.hashimli@weidmueller.  
com

## BA Bosnia and Herzegovina

Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia  
or  
BH ES Elektrosistem d.o.o.  
Palih boraca 104  
78000 Banja Luka  
Telephone number +387 51  
420 340  
Fax number  
elsist@inecco.net  
www.elektrosistem.ba  
BIG electric d.o.o  
Mladena Stojanovića 117A  
78000 Banja Luka  
Telephone number +387  
51926277  
Fax number +387 51926277  
bigelectric@blic.net  
www.bigelectric.ba

## BE Belgium

Weidmüller Benelux B. V.  
Mechelsesteenweg 519 bus  
6 en 7  
1930 Nossegem  
Telephone number +32 2  
752 40 70  
Fax number +32 2 751 36 06  
info@weidmueller.be  
www.weidmueller.be

## BG Bulgaria

Weid-Bul EOOD  
Bul. „Kliment Ohridski“ 13  
1756 Sofia  
Telephone number +359 2  
963 2560  
Fax number +359 2 963  
1098  
sofia@weidbul.com  
www.weidbul.com

## BH Bahrain

Khayber Trading Company  
P.O Box 1976  
Manama  
Telephone number +973  
720747  
Fax number +973 720331  
khayber@batelco.com.bh

## BR Brazil

Weidmüller Conexel do Brasil  
Conexões Elétricas Ltda.  
Av. Presidente Juscelino, 642  
- Piraporinha  
Diadema, São Paulo  
09950-370  
Telephone number +55 (11)  
4366-9600  
Fax number +55 (11) 4362-  
1677  
vendas@weidmueller.com.br  
www.weidmueller.com.br

## BW Botswana

Please contact  
Phambili Interface  
South Africa

## BY Belarus

TECHNIKON Ltd.  
Nezavisimosti pr. 177-9  
220125 Minsk  
Telephone number +375 17  
393-11-77  
Fax number +375 17  
3930080  
wm@technikon.by

## CA Canada

W Interconnections Canada  
Inc.  
10 Spy Court  
Markham Ontario L3R 5H6  
Telephone number +1 (905)  
475-1507 Ext. 9836  
Fax number +1 (905) 475-  
2798  
support@weidmuller.ca  
www.weidmuller.ca

## CG Congo

Please contact  
Phambili Interface  
South Africa

## CH Switzerland

Weidmüller Schweiz AG  
Rundbuckstraße 2  
8212 Neuhausen am  
Rheinfall SH  
Telephone number +41 52  
674 07 07  
Fax number +41 52 674  
07 08  
info@weidmueller.ch  
www.weidmueller.ch

## CL Chile

CPI CHILE LTDA  
Av. Presidente Frei Montalva  
6001, 47 complejo el cortijo  
Santiago - Conchalí  
Telephone number +562  
963 8440  
Fax number +562 963 8440  
cpi@cpichile.cl  
www.cpichile.cl

## CN China

Weidmüller Interface  
(Shanghai) Co. Ltd.  
100 Yutong Road  
25 F. BM Intercontinental  
Business Center  
200070 Shanghai  
Telephone number +86 21-  
22195008  
Fax number +86 21-  
22195009  
customer.hotline@  
weidmueller.com.cn  
www.weidmueller.com.cn

## CO Colombia

Automatización Avanzada  
S. A.  
Carrera 97 No., 24 c - 23  
Bodega 4  
110911 Bogotá-D.C.  
Telephone number +57 (1)  
547-8510  
Fax number +57 (1) 422-  
3044  
comercial@  
automatizacionavanzada.com  
www.  
automatizacionavanzada.com

## CR Costa Rica

ELVATRON S. A.  
la Uruca 400 Norte Banco  
Costa Rica  
San Jose Costa Rica  
Telephone number +506  
2961-060  
Fax number +506 5200-609  
dirk.haase@elvatron.com  
www.elvatron.com

## CZ Czech Republic

Weidmüller s.r.o.  
Lomnického 5/1705  
140 00 Praha 4  
Telephone number +420 244  
001 400  
Fax number +420 244  
001 499  
office@weidmueller.cz  
www.weidmueller.cz

## DE Germany

Weidmüller GmbH & Co. KG  
Ohmstraße 9  
32758 Detmold  
Postfach 30 54  
32720 Detmold  
Telephone number +49 5231  
1428-0  
Fax number +49 5231 14-  
292083  
weidmueller@weidmueller.de  
www.weidmueller.de

## DK Denmark

Weidmüller Danmark  
Vallensbækvej 18A  
2605 Brøndby  
Telephone number +45  
27747800  
kundeservice@weidmuller.dk  
www.weidmuller.dk

## DZ Algeria

SARL INTER ELECTRIC  
1a Angles des Rues Okba Ibn  
Nafaa et Hassi Beida  
2300 Annaba  
Telephone number  
Fax number  
contact@inter-electric.com

## EC Ecuador

Elsystec S. A., Electricidad  
Sistemas y Tecnología  
Vasco de Contreras N35-251  
y Mañosa  
Quito - Pichincha  
Telephone number +593  
22456510  
Fax number +593 22456755  
Elsystec@uio.satnet.net

## EE Estonia

Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Latvia

or

SLO Eesti AS  
11415 Tallinn  
Telephone number +372 6  
272 200  
Fax number  
info@slo.ee

SLO Eesti AS

12618 Tallinn  
Telephone number +372  
622.9119  
Fax number  
elit@elit.ee

Soots Interface OÜ

Pärnu mnt 142  
11317 Tallinn  
Telephone number +372  
609 6933  
Fax number  
info@sootsinterface.ee  
www.sootsinterface.ee

## EG Egypt

Standard Electric (OMEGA)  
1, Abdelhamid Badawy Street  
Heliopolis  
Cairo  
Telephone number +202  
21805111  
Fax number +202 21805600  
stdelec@rite.com

## ES Spain

Weidmüller, S. A.  
Narcis Monturiol 11-13, Pol.  
Ind. Sudoeste  
8960 Sant Just  
Desvern - Barcelona  
Telephone number +34 934  
803 386  
Fax number +34 933 718  
055  
weidmuller@weidmuller.es  
www.weidmuller.es

## FI Finland

Weidmüller Suomi,  
Weidmüller Aktiebolagetin  
sivuliike  
Koy Plaza Vivace  
Äyritie 8C  
FI 15100 Vantaa  
Telephone number +358 20  
7351300  
Fax number +358 800  
114 667  
asiakaspalvelu@weidmuller.fi  
www.weidmuller.fi

## FR France

Weidmüller E. U. R. L.  
2 Boulevard de l'Oise  
CS 31100 CERGY  
95095 CERGY PONTOISE  
Cedex  
Telephone number +33 1 34  
24 55 00  
Fax number +33 1 34 24  
55 01  
mail@weidmuller.fr

## GB Great Britain

Weidmüller Ltd.  
Klippon House  
Centurion Court Office Park,  
Meridian East, Meridian  
Business Park  
Leicester  
LE19 1TP  
Telephone number +44 116  
282 3470  
Fax number +44 116 289  
3582  
marketing@weidmuller.co.uk  
www.weidmuller.co.uk

## GE Georgia

Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.

## GH Ghana

Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.

## GR Greece

G.A. Solutions  
Ippokratous 11 Metamorfsi  
144 52 Athens  
Telephone number +30 210  
2823233  
Fax number +30 210  
2823233  
info@weidmuller.gr  
www.weidmuller.gr

## GT Guatemala

Prestelectro, Prestegard  
Electro, S.A.  
Avenida Petapa 44-22,  
Zona 12  
Guatemala City  
Telephone number +502  
2442-3346  
Fax number +502 2476-8945  
ventas@prestelectro.com

## HK Hong Kong

Weidmüller (Hong Kong)  
Limited Co. Ltd.  
Unit 1617, Metropolis Tower  
No. 10 Metropolis Drive,  
Hung Hom, Kowloon  
Telephone number +852  
3154 8088  
Fax number +852 31548099  
Info-hk@weidmueller.com.hk

## HR Croatia

ElektroPARTNER d.o.o.  
Slavonska avenija 24/6  
HR-10000 Zagreb  
Telephone number +385 (1)  
6184 793  
Fax number +385 (1) 6184  
795  
elektropartner@zg.t-com.hr  
www.elektropartner.hr

## HU Hungary

Weidmüller Kereskedelmi Kft.  
Budapest  
Gubacsi út 6.  
1097  
Telephone number +36 1  
382 7700  
Fax number +36 1 382 7701  
info@weidmueller.hu  
www.weidmueller.hu

## ID Indonesia

PT. Nego Electrindo  
Ruko Mega Grosir Cempaka  
Mas Blok I No. 20 - 22  
Jakarta 10640  
Telephone number +62 21  
42882266  
Fax number +62 21  
42882266  
sales@negoelectrindo.co.id

## IE Ireland

Please contact  
Weidmüller Ltd.  
Great Britain

## IL Israel

A. U. Shay Ltd.  
23/25, Embar Street  
49222 Petach-Tikva  
P.O. Box 1 00 49  
49222 Petach-Tikva  
Telephone number +972  
3-923-3601  
Fax number +972 3-923-  
4601  
shay@uriel-shay.com  
www.uriel-shay.com  
ATEKA Ltd.  
4, Ha Tavor lane Industrial  
area Segula  
49691 Petach-Tikva  
P.O. Box 4710  
Petach-Tikva  
Telephone number +972  
73-200-1311  
Fax number +972 3-924  
4245  
marketing@ateka.co.il  
www.ateka.co.il



You can find all Weidmüller addresses and your local contact on the internet at: [www.weidmuller.com/countries](http://www.weidmuller.com/countries)

Sales company

Representation abroad

without representation abroad

Let's connect.

- IN India**  
Representative Office  
Weidmüller Electronics India Pvt. Ltd.  
No. 9, Union Street, Off. Infantry Road  
BANGALORE  
560 001  
Telephone number +91-80-22860028  
wmi@weidmuller.in  
www.weidmuller.com
- IR Iran**  
Representative Office  
Tamin Ehtajat Fanni Tehran (TAF Co.)  
No. 36, West 4th St., Ettehad Ave. Damavand Rd.  
Tehran - 1658674583, Iran  
Telephone number +9821 77120809  
info@taf-co.com  
http://www.taf-co.com
- IS Iceland**  
Samey Automation Center  
Lyngas 13  
210 Garoabaer  
Telephone number +354 510 5200  
Fax number +354 5 10 5201  
Samey@samey.is  
www.samey.is
- IT Italy**  
Weidmüller S. r.l.  
Via Albert Einstein 4  
20092 Cinisello Balsamo Milano  
Telephone number +39 02 680681  
Fax number +39 02 6124945  
weidmuller@weidmuller.it  
www.weidmuller.it
- JM Jamaica**  
Please contact  
W Interconnections Inc.  
United States
- JO Jordan**  
Billeh Electricals Mat. Co.  
PO Box 4343  
Amman  
Telephone number +962 6 4656 987  
Fax number +962 6 4649 216
- JP Japan**  
Nihon Weidmüller Co. Ltd.  
Sphere Tower Tennoz 2-2-8 Higashi-Shinagawa, Shinagawa-ku  
Tokyo  
140-0002  
Telephone number +81 3 6711 5300  
Fax number +81 3 6711 5333  
info@weidmuller.co.jp  
www.weidmuller.co.jp
- KE Kenya**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH & Co. KG  
South Africa.
- KG Kyrgyzstan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- KR Korea**  
Weidmüller Korea Co. Ltd.  
9th floor  
429, Teheran-ro, Gangnam-Gu  
Seoul 135-721  
Telephone number +82 2-516-0003  
Fax number +82 2-516-0090  
info@weidmuller.co.kr  
www.weidmuller.co.kr
- KW Kuwait**  
Kana Controls General Trading & Contracting Co. W. L. L.  
Al Rai Industrial Area, Plot 28-30, St. 31  
13016 Safat  
B.P. 25593  
Telephone number +965 4741373  
Fax number +965 4741537  
info@kanacontrols.com
- Petroleum Services Co. W.L.L.  
Kuwait Trade Free Zone Area  
P.O. Box 4098 Safat 13041
- Telephone number +96524610801/2/3 ext. 208 II  
Fax number +96524613754  
psc-systems@petserv.net
- KZ Kazakhstan**  
Please contact  
Weidmüller Group  
Russia
- LB Lebanon**  
Progress Engineering & Trading Enterprises  
Al Nahr Street  
Beirut 11-1111  
Telephone number +961 1 444 664  
Fax number +961 1 561 880  
progress@inco.com.lb
- LT Lithuania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH & Co. KG  
Latvia
- or
- ELEKTROS IRANGA  
Tinklu g. 29 a  
LT-5319 Panevezys  
Telephone number +370 (45) 582 828  
Fax number +370 (45) 582 727  
info@eliranga.lt
- UAB „SLO Lithuania“  
Vilkpėdės g. 4  
LT-LT-03151 Vilnius  
Telephone number +370 5 215 00 70  
Fax number +370 5 215 00 71  
biuras@slo.lt
- LU Luxembourg**  
Please contact  
Weidmüller Benelux B. V.  
Netherlands
- LV Latvia**  
SIA Abi4  
Daugavgrivas 49 k3  
Riga, LV-1007  
Telephone number +371 674 70999  
Fax number  
abi\_4@tvnet.lv
- Representative Office  
Weidmüller Interface GmbH & Co. KG  
Udens str. 12-118  
Riga, LV-1007  
Telephone number +371 29254766  
Fax number  
lgonis.rudaks@weidmuller.com  
www.weidmuller.com
- MA Morocco**  
Sofimed  
137, Bd Moulay Ismail Roches Noires  
20290 Casablanca  
Telephone number  
Fax number  
contact@sofimedmaroc.com
- MD Moldova**  
Inoxpa Solutions SRL  
20, Igor Vieru street  
MD-2075 Chisinau  
Moldova  
Telephone number +373 (22) 866665  
Fax number +373 ( 22) 866663  
atiuleanu@gmp-moldova.com  
www.gmp-moldova.com
- ME Montenegro**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH & Co. KG  
Serbia.
- MG Madagascar**  
Please contact  
Phambili Interface  
South Africa
- MK Macedonia**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH & Co. KG  
Serbia
- or
- ELEKTRO - SMK dooel  
UL. III Makedonska brigada  
b.b.  
1000 Skopje  
Telephone number +389 22460295  
Fax number  
Elektro-smk@telekabel.net.mk
- MN Mongolia**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- MT Malta**  
E. S. S., Electrical Supplies & Services Ltd.  
San Gwakkim Road  
Mriehal  
Telephone number +356 21255777  
Fax number +356 21255999  
robert.agiuss@ess.com.mt
- MU Mauritius**  
Mubelo Electrical Ltd.  
Office 26, Gateway building,  
St Jean Road  
Quatre Bornes  
Mauritius  
Telephone number +230 4670989  
Fax number +230 4654051  
richard.mubelo@orange.mu
- MW Malawi**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH & Co. KG  
South Africa.
- MX Mexico**  
W Interconnections S. A.  
DE C. V.  
Blvd. Hermanos Serdán 698,  
Col. San Rafael Oriente  
72029 Puebla  
Telephone number +52 (222) 268 6227  
Fax number +52 (222) 286 6242  
clientes@weidmuller.com.mx
- MY Malaysia**  
Connect Plus Technology  
Sdn Bhd  
No. 43, Jalan PJS 11/22,  
Bandar Sunway  
46150 Petaling Jaya  
Selangor Darul Ehsan  
Telephone number +60 3 5633 7363  
Fax number +60 3 5633 6562  
paul@cptech.com.my  
www.cptech.com.my
- MZ Mozambique**  
Please contact  
Phambili Interface  
South Africa
- NA Namibia**  
Please contact  
Phambili Interface  
South Africa
- NG Nigeria**  
Please contact  
Weidmüller Interface GmbH & Co. KG  
South Africa
- NL Netherlands**  
Weidmüller Benelux B. V.  
Franciscusweg 221  
1216 SE Hilversum  
P.O. Box 1505  
1200 BM Hilversum  
Telephone number +31 35 626 12 61  
Fax number +31 35 623 20 44  
info@weidmuller.nl  
www.weidmuller.nl
- NO Norway**  
Sivilingeniør J.F. Knudtzen AS  
Billingstadsetta 97  
1396 Billingstad  
PO Box 160  
1378 Nesbru  
Telephone number +47 66 98 33 50  
Fax number +47 66 98 09 55  
firmapost@jfknudtzen.no  
www.jfknudtzen.no
- NZ New Zealand**  
Cuthbert S. Steward Ltd.  
27 Te Puni Street  
Petone  
PO Box 38496  
Wellington Mail Centre 5054  
Telephone number (04) 568 6156  
Fax number (09) 489 1752  
csl@cuthbertsteward.co.nz
- Cuthbert S. Steward Ltd  
4 Fred Thomas Drive  
Aon Building, Ground Floor,  
South Entry  
Takapuna  
PO Box 100 338  
North Shore City 745  
Telephone number (09) 489 1751  
Fax number (04) 568 6056  
cslak@cuthbertsteward.co.nz
- OM Oman**  
DAN INTERNATIONAL LLC.  
Ghala St. 111  
BP 2901  
Seeb  
Telephone number +968 5036 77  
Fax number +968 5037 55  
yedu@danintl.com
- PE Peru**  
IMPEXINCA S.A.C.  
Calle Ortiz de Zevallos No.  
105, Urb. San Antonio  
18  
Lima, Miraflores  
Telephone number +51 1 447 5608  
info@impexinca.pe  
www.impexinca.pe  
J & W CIA. S. A.  
Calle 6 Mz. D Lte. 23, Urb.  
Ind. Grimanesa  
01  
Callao  
Telephone number +51 1 572 2539  
Fax number +51 1 572 0152  
contacto@jwcia.com  
www.jwcia.com
- PH Philippines**  
Enclosure Systems Specialists  
Inc.  
2276 Don Chino Roces  
Avenue Extension  
Room 103/105 Narra Building  
1231 Makati City  
Telephone number +63 2 813 8580  
Fax number +63 2 813 8596  
sales\_encsys@pltdsl.net  
www.enclosuresystemsph.com
- PK Pakistan**  
Automation Controls (Pak)  
Apartment No. 33 C III,  
Chensab Block, Allama Iqbal  
Town  
Lahore  
Telephone number +92 42 37809948  
Fax number +92 42 37809950  
nadeem@acpak.com.pk  
www.acpak.com.pk
- PL Poland**  
Weidmüller Sp. z o. o.  
ul. Ogrodowa 58  
00-876 Warszawa  
Telephone number +48 22 510 09 40  
Fax number +48 22 510 09 41  
biuro@weidmuller.com.pl  
www.weidmuller.pl
- PR Puerto Rico**  
Please contact  
W Interconnections Inc.  
United States
- PT Portugal**  
Weidmüller Sistemas de Interface S. A.  
Estrada Outeiro Polima, R.  
Augusto Dias da Silva, Lote B - Esc. 2.  
São Domingos de Rana  
2785-515 Abóboda  
Telephone number +351 214 459 191  
Fax number +351 214 455 871  
weidmuller@weidmuller.pt  
www.weidmuller.pt
- PY Paraguay**  
Please contact  
CPI SA  
Argentina
- QA Qatar**  
Doha Motors  
PO Box 145  
Telephone number +974 4651441  
Fax number +974 4654579  
dmtctech@qatar.net.qa  
http://www.dohamotorsgroup.com/td.html
- RO Romania**  
Representative Office  
Weidmüller Interface GmbH & Co. KG  
Inescu Crum Street, No. 1, 1st Tower, 1st Floor,  
Office 4  
500446 Brasov - Brasov  
Business Park  
Telephone number +40 (268) 446 222  
Fax number +40 (268) 446 224  
claudiu.totea@weidmuller.com  
www.weidmuller.ro
- RS Serbia**  
Representative Office  
Weidmüller Interface GmbH & Co. KG  
Ustanička 189, III sprat  
lokal 7a  
11050 Beograd  
Telephone number +381 112885274  
Fax number +381 112885274  
zoran.rabrenovic@weidmuller.com
- TeLa Elektrik d.o.o.  
Ul. Dr. Drage Ljočić 6  
Beograd  
Telephone number +381 11 2772 415  
Fax number +381 11 2772 850  
office@tela.rs  
www.tela.rs

# Addresses worldwide

Let's connect.

**RU Russia**  
Weidmüller Group  
7/10 Khlebozavodskiy  
Passage,  
Moskau  
115230  
Telephone number +7 495  
280 72 71  
Fax number +7 495 280  
72 71  
Info@weidmueller.ru  
www.weidmueller.ru

**SA Saudi Arabia**  
Al Abdulkarim Holding Co.  
P.O. Box 4  
Dammam 31411  
Telephone number +966 3  
8337 110  
Fax number +966 3  
8829547  
E-mail salehsk@akh.com.sa  
www.weidmueller.ae

Saudi Electric Supply  
Company (SESCO)  
P.O. Box 32 98  
Al Khobar 31952  
Telephone number +966 3  
8829546 Ext. 3030  
Fax number  
E-mail Safdar.Malik@sescogex.com  
www.sescogex.com

**SE Sweden**  
Weidmüller AB  
Axel Danielssons väg 271  
BOX 31025  
SE-200 49 Malmö  
Telephone number +46 77-  
143 00 44  
Fax number +46 40-37 48 60  
info@weidmuller.se  
www.weidmuller.se

**SG Singapore**  
Weidmüller Pte. Ltd.  
70 Bendemeer Road  
# 04-03 Luzerne Building  
Singapore 339940  
Telephone number +65 6841  
53 11  
Fax number +65 6841 5377  
info@weidmuller.com.sg  
www.weidmuller.com.sg

**SI Slovenia**  
Elektrospoji d. o. o.  
Stegne 27  
SI- 1000 Ljubljana  
Osrednjeslovenska  
Telephone number +386 1  
511 3810  
Fax number +386 1 511  
1604  
info@elektrospoji.si  
www.elektrospoji.si

**SK Slovakia**  
ELEKTRIS s.r.o.  
Elektrárenská 1  
831 04 Bratislava  
Telephone number +421  
2/4920 0113  
Fax number +421 2/4920  
0119  
bratislava@elektris.sk

**SV El Salvador**  
Prestegard Electro  
11 Avenida Norte No. 240  
Edificio Salazar No. 2  
San Salvador  
Telephone number +503  
2271 1690  
Fax number +503 2221  
3851  
prestegard@navegante.com.sv

**SY Syria**  
Please contact  
Weidmuller Middle East FZE  
United Arab Emirates

**SZ Swaziland**  
Please contact  
Phambili Interface  
South Africa

**TH Thailand**  
Pisanu Engineering Co. Ltd.  
Kwang Dingaeng, Khet  
Dingaeng  
800/2 Soi Trakulsuk, Asoke-  
dindaeng Road  
Dindaeng, Bangkok  
10400  
Telephone number +66 2  
248 2896  
Fax number +662 105 6301  
ecsales@pisanu.co.th  
www.pisanu.co.th

Representative Office  
Weidmüller Pte. Ltd.  
37/F, Sathorn Square Building  
98 North Sathorn Road  
Bangkok, Silom Bangrak  
10500  
Telephone number +66 2  
105 6300  
Fax number +66 2 642 9220  
info@weidmuller.com.sg

**TJ Tajikistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.

**TM Turkmenistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.

**TN Tunisia**  
Please contact  
Weidmüller E. U. R. L.  
France

**TR Turkey**  
Weidmüller Elektronik Ticaret  
Ltd. Sirketi  
Kavacik Mah. Orhan Veli Kanik  
Caddesi 9/1  
34810 Beykoz / Istanbul  
Telephone number +90 (216)  
537 10 70  
Fax number +90 (216) 537  
10 77  
info@weidmuller.com.tr  
www.weidmuller.com.tr

**TW Taiwan**  
Please contact  
Weidmuller (Hong Kong)  
Limited Co. Ltd.  
Hong Kong

**TZ Tanzania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.

**UA Ukraine**  
LLC WM UKRAINE  
Levanevskogo str. 6  
Kiev  
3058  
Telephone number +38 044  
490 32 48  
Fax number  
info@wm-ua.com.ua  
wm-ua.com.ua/

Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Z. office 303  
7-D, Zdolbunivska str.  
Kiev, 2081  
Telephone number  
(mobile) +38 050 440 25 24  
info.ua@weidmueller.com

**US United States**  
W Interconnections Inc.  
821 Southlake Boulevard  
Richmond Virginia 23236  
Telephone number +1 (804)  
794-2877  
Fax number +1 (804) 379-  
2593  
info@weidmuller.com  
www.weidmuller.com

**UY Uruguay**  
REWO Uruguay S. A.  
AV. Bolivia 2001Esq  
Rocafuerte  
11300 Carrasco Montevideo  
Telephone number +598  
2604 8439  
Fax number +598 2604  
8439  
rewo@rewooruguy.com.uy

**UZ Republic of Uzbekistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.

**VE Venezuela**  
Somerinca C. A.  
Corazon de Jesus - 3ra  
Transversal con calle el  
Carmen- Los Dos Caminos  
Caracas 1070-A  
Telephone number +58  
2122352748  
Fax number +58  
2122399341  
klocmoeller@cantv.net  
www.somerinca.com

**VN Vietnam**  
AUMI Industrial Equipment &  
Automation Company Limited  
E1, La Thanh Hotel  
218 Doi Can Street  
Lieu Giai Ward, Ba Dinh  
District  
Hanoi City  
Telephone number +84 4  
37 628601  
Fax number +84 4  
62661391  
aumi@aumi.com.vn  
www.aumi.com.vn

Representative Office  
Weidmüller Pte. Ltd.  
Level 16 Saigon Tower  
Building  
29 Le Duan Street  
District 1  
Ho Chi Minh  
Telephone number +848  
3520 7717  
Fax number +848 3520  
7604  
info@weidmuller.com.sg

**ZA South Africa**  
Phambili Interface  
PO Box 193  
1609 Johannesburg, Edenvale  
5 Bundo Road, Sebenza  
1610 Johannesburg  
Telephone number +27 (11)  
4521930  
Fax number  
info@weidmuller.co.za  
www.weidmuller.co.za

Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
210 Amarand  
Avenue, Pegasus Building  
181 Pretoria, waterkloof Glen  
ext 2 -  
Telephone number +27 12  
003 2906  
Fax number +27 (11)  
4526455  
Jacques.Vosloo@weidmueller.  
com  
www.weidmueller.com

**ZM Zambia**  
Please contact  
Phambili Interface  
South Africa

**ZW Zimbabwe**  
Please contact  
Phambili Interface  
South Africa