

Keep it Simple



Print with SELPHY

www.canon-asia.com/selphy

SOUTH & SOUTHEAST ASIA REGIONAL HEADQUARTERS

CANON SINGAPORE PTE. LTD.

1 Harbourfront Avenue #04-01 Keppel Bay Tower Singapore 098632

Tel: 65-6799 8888 Fax: 65-6221 7577

www.canon-asia.com

CANON OFFICES

MALAYSIA

Canon Marketing
(Malaysia) Sdn. Bhd.

Tel : 603-78446000

Fax: 603-78450505

SINGAPORE

Canon Singapore Pte. Ltd.
Domestic Operations

Tel: 65-6799 8888

Fax: 65-6799 8882

www.canon.com.sg

THAILAND

Canon Marketing
(Thailand) Co., Ltd.

Tel: 66-2-3449999

Fax: 66-2-3449922

www.canon.co.th

VIETNAM

Canon Marketing Vietnam Co. Ltd.

Ho Chi Minh City

Office & Showroom

Tel: 84-8-382 00466

Fax: 84-8-382 00477

www.canon.com.vn

Hanoi Branch Office

Tel: 84-4-7711 677

Fax: 84-4-7711 678

CANON BUSINESS PARTNERS

BANGLADESH

J.A.N Associates

Tel: 880-2-8611444

Fax: 880-2-8610410

BRUNEI

Interhouse Company

Tel: 673-2-653001

Fax: 673-2-653003

CAMBODIA

i-Click (Cambodia) Pte. Ltd

Tel: 855-23-996638

Fax: 855-23-996639

INDONESIA

PT. Datascip

Tel: 62-21-2664-8999

Fax: 62-21-6544811/12/13

www.canon.co.id

MALDIVES

SIMDI Company Pvt. Ltd.

Tel: 960-324819

Fax: 960-318433

MYANMAR

Myanmar Golden Rock
International Co., Ltd.

Tel: 95-1-202092/3/4

Fax: 95-1-202079

NEPAL

Primax International, Inc.

Tel: 977-1-4224079

Fax: 977-1-4429358

PAKISTAN

MBM International

Tel: 92-21-322777093/4

Fax: 92-42-37530948

SRI LANKA

Metropolitan Office (Pvt.) Ltd.

Tel: 94-011-4700200

Fax: 94-011-4700266

0169W253

SELPHY CP900

COMPACT PHOTO PRINTER

Canon

Delighting You Always

Minimum Effort



Maximum Fun



NEW



Keep it Simple




Print with SELPHY

SELPHY CP900

COMPACT PHOTO PRINTER

Fun Printing Made Simple

Photo printing is now more convenient and exciting with the new SELPHY CP900. This compact photo printer makes daily activities – from organizing items to decorating rooms and even creating personalized gifts – fun and easy with new features like **Wi-Fi printing** via smartphones and cameras, and **54 x 54mm label** fun-sized photo print outs. What's more, it comes in three awesome colors: White, Pink and Black!

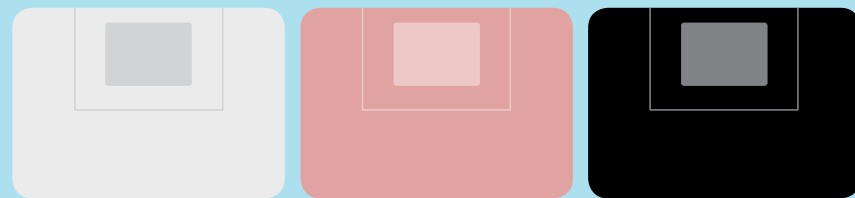

Get Organized Save Time



LABEL YOUR STUFF

The new Wi-Fi direct printing function lets you find any item easily. All you need to do is connect SELPHY to a smart device or camera, take a picture of your possessions, send to print and stick the photos wherever you need.

For more details on Wi-Fi, please visit www.canon-asia.com/wificonnect



Snap & Send



Print



Your shoes organized
and easily found.



KP-36IP
Postcard-sized
paper (36 pieces)




Whip Up Send Out




SHARE YOUR ARTISTRY

Make recipe cards of your specialty foods with postcard-sized print outs. Simply snap a shot of your dish, print it and spread the goodness by posting it out to your family and friends.

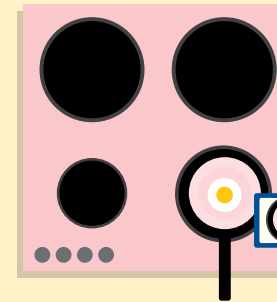

Cook & Snap

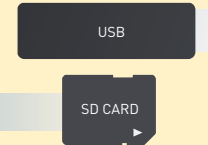

Transfer



Your recipe cards printed and ready to be shared.




Get Creative Be Personal



PERSONALIZE YOUR GIFT

Create a personalized gift or birthday card for that special someone. Let your imagination run free and spice up your pictures by adding frames, speech bubbles or clipart.

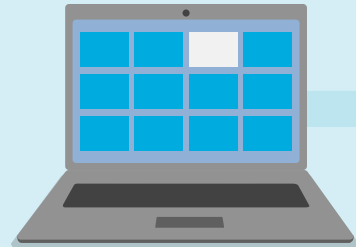

Select



Add



Your heart-felt words spoken
with your gift of love.

KP-108IN
Postcard-sized
paper (108 pieces)



Requires installation of Compact Photo
Printer Solution disc bundled CD.


Spruce Up Add Radiance



DECORATE YOUR SPACE

Beautify your room any way you like with Photo Collage. Select, preview memorable shots in the 2.7" LCD tilt-up monitor and print them out.

- Select either 8 or 20 photos and print in Portrait or Landscape, with White or Black border

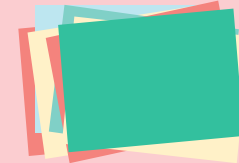


Collate



Print



 Your room beautifully decorated with memories.




Capture Fun Get Inspired



STICK YOUR IDEAS

Liven up your work space with 54 x 54mm label print outs. Snap up interesting sights on-the-go with any photography app on your smartphone, send it to print and make your own inspiration board.

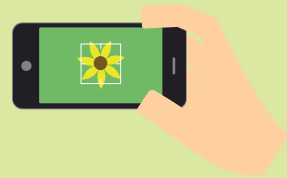

Snap



Print



Your desk filled with inspirational works.



 
KC-181S
Card-sized square
label (18 pieces)

More Choices, Lasting Enjoyment



KEEP YOUR MEMORIES

Keep your loved one closer by printing wallet-sized photos with up to 28 ID Photo layout options. What's more, you'll get high-quality and splash-proof print outs that last for 100 years – thanks to the unique Dye Sublimation printing process and protective overcoating.



Print

Cut



Dye-Sub



ID Layout

100
YEARS
PRINT

Take your loved one everywhere you go.

Enhance Your Printing Experience



DUST PROOF CASING



 
DCP-CP100
Dust Cover



OPTIONAL CHARGER / BATTERY



CG-CP200
External Battery Charger



NB-CP2L
Battery Pack



INK / CARTRIDGES (FULL RANGE)

CARD SIZE



KC-181F
Card-sized sticker labels (Full-sized, 18 pieces)



KC-181L
Card-sized sticker labels (8 labels per piece, 18 pieces)



KC-361P
Card-sized paper (36 pieces)

POSTCARD SIZE



KP-1081N
Postcard-sized paper (108 pieces)



KP-361P
Postcard-sized paper (36 pieces)

SQUARE LABEL SIZE



KC-181S
Card-sized square label (18 pieces)

SELPHY CP900 Technical Specifications

PRINTING METHOD GENERAL SPECIFICATIONS	Dye-sublimation thermal print method (with overcoating)
	Resolution 300 x 300 dpi
	Gradation 256 shades per color
	Dedicated ink and paper integrated cartridge - Postcard size (with an address field on reserve side): KP-361P - Postcard size (with Canon logo on reserve side): KP-721N, KP-1081N - L size: KL-361P - Card Size: KC-361P - Card Size (with full page sticker): KC-181F - Card Size (with 8 stickers per page): KC-181L - Card Size (with square sticker): KC-181S* * only available with CP900
	Feeding System Automatic paper feeding from the paper cassette
	Ejection System Automatic paper ejection on top of the paper cassette
	Print Size - Postcard size, borderless: 100 x 148mm (3.94 x 5.83 in.) - Postcard size, with border: 91.4 x 121.9mm (3.60 x 4.80 in.) - L size, borderless: 89 x 119mm (3.50 x 4.69 in.) - L size, with border: 79.2 x 105.3mm (3.12 x 4.15 in.) - Card size, borderless (including stickers): 54 x 86mm (2.13 x 3.39 in.) - Card size, with border (including stickers): 50 x 66.7mm (1.97 x 2.63 in.) - 8 stickers per page: 22 x 17.3mm (0.87 x 0.68 in.) - Square Sticker: 54 x 54mm (2.1 x 2.1 in.)
	Printing Modes - Standard print (selection of individual images and number of copies for batch printing) - All image print (selection of all images and number of copies for batch printing) - DPOF image print - ID Photo
	Print Settings/ Setting Changes Date, Red-eye correction, Bordered, Borderless, Layout (1-up, 2-up, 4-up, 8-up, Index, Shuffle), Smooth skin, Image optimize, (Manual) brightness adjustment, My Colors (Off, Vivid, Neutral, Positive Film, Sepia, Black & White), Date format, Power saving (On/Off), Language (13 languages)
	Wireless LAN settings Initial Settings, Comm. Mode, Access Point Connect, Confirm Settings, Other Settings, Reset Settings

INTERFACE	Card Slots	1 slot (Playback images can be viewed on the LCD monitor)
	Supported memory cards: Without adapter	SD / SDHC / SDXC / MMC / MMCplus / HC MMCplus
	Via adapter	miniSD / miniSDHC / microSD / microSDHC / microSDXC / RS-MMC / MMCmobile / MMCmicro
	USB Flash Drive	Supported
	Direct to computer	Hi-Speed USB (Mini-B connector)
PRODUCT SPECIFICATION	Direct to camera (PictBridge)	Hi-Speed USB (Type A connector) Wireless/Wireless LAN (DPS over IP Standard compliant)
	Wireless	Wireless LAN (IEEE802.11b/g* compliant) *Applied channel: 1 - 11 ch Infrastructure connection Ad hoc connection
	LCD Monitor	2.7-inch TFT type color (with adjustment tilt mechanism)
	Operating Environment	5 - 40°C (41 - 104°F), 20 - 80%RH
	Power Source	AC Adapter CA-CP200B Charge Adapter CG-CP200 Battery Pack NB-CP2L (sold separately)
PRODUCT SPECIFICATION	Power Consumption	60W or less (4W or less when in idle mode)
	Dimensions (excluding protrusions)	178 x 127 x 60.5mm (7.01 x 5 x 2.38 in.)
	Weight (printer only)	Approx: 810g (28.6oz.)



White



Pink



Black