

# MICRO-SDHC-UHS1-16GB



## **Introduction:**

High capacity and high performance data storage and communication media.

This memory card is designed for wide range of applications. Compatible devices include cell-phone, MP3 players, MP4 players, digital cameras, camcorder, smartphone, tablet, GPS, Electronic books, ....

Excellent to capture RAW+JPEG and High Definition video.

This card can be used also with motherboard to store data programs. This card can be used for any other applications.

## **Features:**

Capacity : 16 Gbits

Type : micro SDHC (Compatible with SD cards reader/writer -> provided with SD/SDHC card adapter)

Speed class : UHS-1 & C10

Compatibility USB2.0 and USB3.0

Read speed USB2.0 : 20 Mb/s

Write speed USB2.0 : 8 Mb/s

Read speed USB3.0 : 50 Mb/s

Write speed USB3.0 : 10 Mb/s

Model : 16GTFC10UHS


Supply voltage : 2,7V to 3,6V

Durability : 10.000 insertion/removal cycles.

Operating temperature : 0°C at +70°C.

Storage temperature : -40°C at +85°C.

Dimensions : 15,0 x 11,0 x 1,0mm

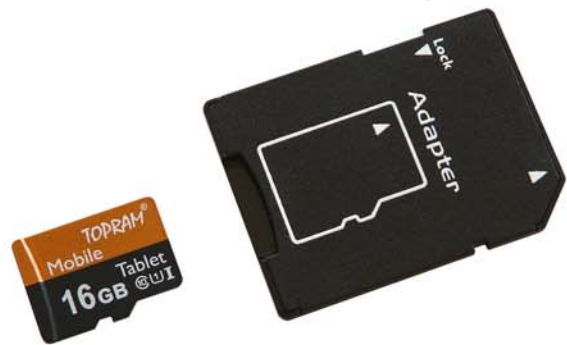

## **Others products:**

MICRO-SDHC-UHS1-16GB



MICRO-SDHC-UHS1-32GB



MICRO-SDXC-UHS1-64GB



## **Item includes:**

Micro SDHC UHS1 card in a packaging.

SD/SDHC card adapter.

Technical datasheet available in English.

**Products informations : [www.seeit.fr](http://www.seeit.fr)**

**Distributors : [www.rs-components.com](http://www.rs-components.com)**