

ID PAL™ Labeling Tool

Professional Labeling with a Difference

► Labels that Stick ► Easy to Use ► Saves Time and Money



ID PAL Labeling Tool

Part Number	Description
81000 IDPAL	ID PAL Labeling Tool - North America*
81001 IDPAL-INTL	ID PAL Labeling Tool - International*

* Includes full label cartridge (PAL-750-439)

ACCESSORIES

Part Number	Description
81002 IDPAL-AC	ID PAL AC Adapter
81003 IDPAL-IG	ID PAL Impact Guards
81004 IDPAL-HC	ID PAL Hardside Carrying Case

SYMBOLS

Press **FUNCTION** + Character

Character	Symbol	Character	Symbol	Character	Symbol
A	!	K	'	U	~
B	@	L	.	V	²
C	#	M	"	W	φ
D	\$	N	/	X	±
E	%	O	\	4	¢
F	&	P	°	5	€
G	*	Q	—	6	∞
H	(	R	±	7	-
I	)	S	'	8	+
J	:	T	Ω	9	=

Prints as 

ID PAL is an affordable, easy-to-use, portable thermal transfer printer designed for the field, not the office. The rugged design has been tested to withstand harsh environments and a tough four foot drop test to concrete.

ID PAL uses Brady high performance labeling materials. The labels stay in place on your toughest surfaces, from wire and cable to highly textured plastic. As a result ID PAL eliminates the confusion caused by faded, smeared or poorly written labels, or labels that fall off leaving unidentified wires.

- Prints Brady-quality labels
- Easy-to-peel labels
- Fits great in your hand
- Job-tough construction
- Easy-to-see bright red color
- Quick, top-load, drop-in cartridge
- Built-in industrial cutter
- Intuitive keyboard with electrical and datacomm symbols
- Special wire marking mode with 10 preset lengths
- Prints upper and lower case characters
- Multiple line printing and serialization
- Automatic shut-off
- Six month warranty (12 months if registered)

SPECIFICATIONS

Print method:	Thermal transfer (non smearing)
Weight:	1.2 lbs. (0.55 kg) with batteries and tape cartridge included
Dimensions (L x W x H):	9.0 x 4.5 x 2.5 inches (228.6 x 114.3 x 63.5 mm)
Power source:	6 AA-size batteries print over 3500 1" (25.4 mm) labels
Operating temperature:	40° - 120° F (4° - 49° C)
Agency Approvals:	FCC Class A approved

FIVE FONT SIZES

7	POINT
10	POINT
14	POINT
20	POINT
28	POINT

▶ LABELS FOR MULTIPLE APPLICATIONS

Choose from Three Label Types

WIRE



- ▶ Built-in leader for wrapping wire/cable
- ▶ Choose from 10 pre-programmed lengths: 0.75", 1", 1.2", 1.5", 2", 2.5", 3", 4", 5", 6"




BANNER



- ▶ Prints up to two lines of text

▶ EASY-PEEL LABEL

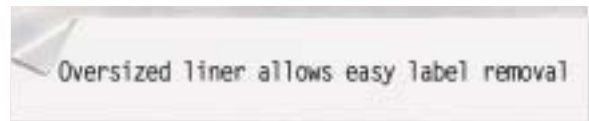

GENERAL



- ▶ Prints up to four lines of text

▶ LESS LABEL WASTE RESULTS IN MORE LABELS



ID PAL label



Competitor label

LABEL CARTRIDGE SELECTION CHART

Application	Material/Color	Max. Service Temperature	3/8" (9mm)	Label Width 1/2" (12mm)	3/4" (9mm)	Roll Length Feet (m)	Agency Approvals
■ ■ ■ ■ ■	Nylon Cloth B-499 / Black on White	194 (90) 30 days	PAL-375-499+	PAL-500-499+	PAL-750-499+	19' (5.8)	UL
■ ■ ■ ■ ■	Vinyl B-439 / Black on White*	104 (40) 30 days	PAL-375-439+	PAL-500-439+	PAL-750-439+	21' (6.4)	UL
■ ■ ■ ■ ■	Polyester B-430 / Black on Clear	212 (100) 30 days	PAL-375-430+	PAL-500-430+	PAL-750-430+	21' (6.4)	UL
■ ■ ■ ■ ■	Polyester B-423 / Black on White	248 (120) 30 days	PAL-375-423+	PAL-500-423+	PAL-750-423+	21' (6.4)	UL

Plus... each cartridge comes preloaded with its own application-specific ribbon.

* Available in other colors

† Catalog Number

Application Key

■	Smooth/Flat Surface	■ ■ ■ ■ ■	Textured Surface
■ ■ ■ ■ ■	Wire/Cable/Curved Surface	■ ■ ■ ■ ■	Highly Textured Surface



Identification Solutions
& Specialty Tapes

www.bradyid.com

Australia 1-800-620-816
Belgium 32-(0)-152-457-811
Brazil 55-11-3686-4720
Canada 1-800-263-6179
China (Beijing) 86-10-6517-1260
China (Wuxi) 86-510-528-2222
England 44-(0)-1295-228-200
France 00-33-1-69-29-67-00

WORLDWIDE LOCATIONS

Germany 49-(0)-607-196-03
Hong Kong 852-2359-3149
Italy 39-02-967-00-507
Japan 81-45-461-3600
Korea 82-2-400-8418
Latin America 1-414-540-5560
Malaysia 60-4-283-3980
Mexico 525-399-6963

New Zealand 61-2-8717-2200
Philippines 632-658-2077
Singapore 65-775-2077
Sweden 46-(0)-859-005-730
Taiwan 88-(6)-2-2345-1430
Thailand 66-2-943-0777
U.S.A. 1-800-537-8791



Y95178B

www.bradyidpal.com

©2002 BRADY Worldwide, Inc. Printed in U.S.A.
Specifications subject to change without notice.
All rights reserved. Y95178B
3-KK-02-VAM-10 Effective 3-02
AN ISO REGISTERED COMPANY