


# Datasheet

## New 5.0mm Plug Straight 15A 9 way

RS Stock 874-4799



### Dimensions: (mm)

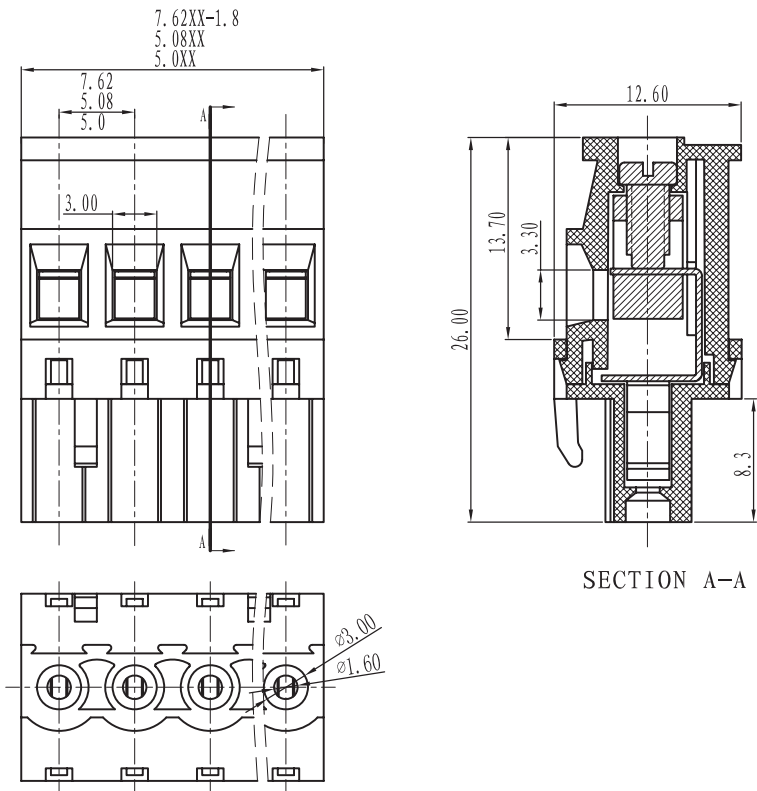



ENGLISH

## Specifications

### Electrical

Standard: UL IEC  
Rated voltage: 300V 320V  
Rated current: 15A 20A  
Contact resistance: 20m $\Omega$   
Wire range: 28-14AWG 2.5mm<sup>2</sup>  
Withstanding voltage: AC2000V/1Min  
Insulation resistance: 500M $\Omega$ /DC500V

### Mechanical

Temp.Range: -40° C~+105° C  
Torque: 0.5Nm(4.5lb`in)  
Strip length: 7-8mm

### Dimensions

Pitch: 5.0mm, 5.08mm, 7.62mm  
Poles: 02P-24P

### Material

Housing: PA66, UL94V-0  
Screws: M3, steel Zinc plated  
Clamp: Brass, Ni plated  
wire guard: Phosphor bronze, Ni plated