

HAND HELD CASES

2900 Series Sloped Cases


Scratch resistant desktop or hand-held enclosures with recess in lid. Ideal for mobile electronics that require a battery compartment.

- Lid, base and battery lid moulded in high grade ABS
- Lid mounted by four M3 machine screws
- Angled LCD Display area
- Sliding battery compartment lid
- Recess in lid for membrane keypads or overlays



SPECIFICATION	
Materials	Lid, base and battery lid in high grade ABS
Operating Temperature	Resistant to temperatures of up to 85°C
Protection class	IP54
Standard colours	Grey or Black. Ivory to order
Standard unit includes	Lid & base Battery compartment lid 4 x M3 machine screws 4 x rubber feet

BLACK	GREY	LENGTH	WIDTH	HEIGHT
BIM2901-BLK/BLK	BIM2901-GY/GY	165mm	87mm	24mm

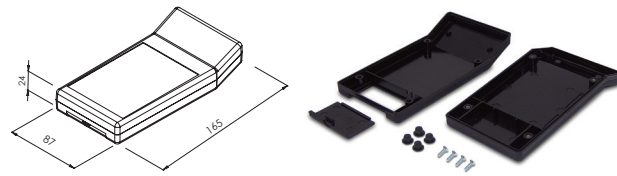

2910 Series Mobile Cases


Functional hand-held ABS cases with recessed lid and a battery compartment.

- Lid and base moulded in high grade ABS
- Lid mounted by four M3 machine screws
- Snap-on battery compartment lid
- Battery compartment for two AA, AAA or one PP3 battery
- PCB pillars in base
- Recess in lid for membrane keypads or overlays



SPECIFICATION	
Materials	Lid, base and battery lid in high grade ABS
Operating Temperature	Resistant to temperatures of up to 85°C
Protection class	IP54
Standard colours	Light grey similar to RAL 7035 or black similar to RAL 9004
Standard unit includes	Lid & base Battery compartment lid 4 x M3 machine screws 4 x self-tapping PCB screws

BLACK	GREY	LENGTH	WIDTH	HEIGHT
CHHMC01BK	CHHMC01GY	105mm	61mm	28mm
CHHMC02BK	CHHMC02GY	145mm	80mm	34mm

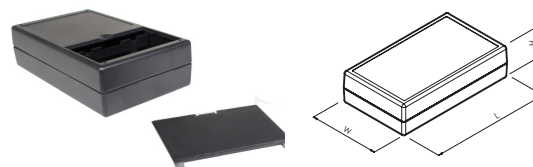

UNIVERSAL ENCLOSURES

HAND HELD CASES

HEAVY DUTY ENCLOSURES

DIN RAIL ENCLOSURES

INTERFACE SUPPORTS

ELECTRICAL ENCLOSURES

DIECAST & METAL ENCLOSURES

DESKTOP & INSTRUMENT CASES

POTTING BOXES

19" ENCLOSURES

19" CABINETS

DEVELOPMENT BOARD ENCLOSURES

CUSTOM SIZED ENCLOSURES

CUSTOM SERVICES