
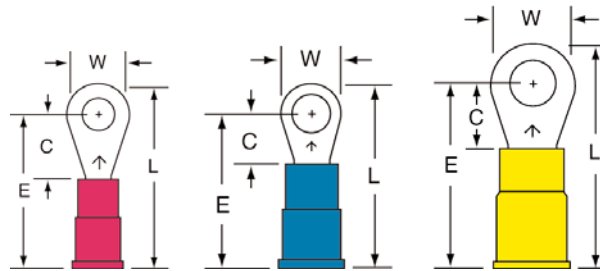


## Vinyl Insulated Butted Seam – Ring Tongues

**Terminal Type** Ring  
**Terminal Style** Standard  
**Insulation Material** Vinyl  
**Barrel Style** Butted  
**EU RoHS** Yes  
**Agency Approval**   
**Manufacturing Origin** 



Terminals, Kits and Tools: 3M™ Highland™ Ring Tongues

Product No.	UPC	Conductor Size	Stud Size	Terminals per Bag	Bags per Case
RV18-6C	054007-70245	22–18 AWG	6	100	5
RV18-6L	054007-70336	22–18 AWG	6	50	10
RV18-10C	054007-70247	22–18 AWG	10	100	5
RV18-10L	054007-70338	22–18 AWG	10	50	10
RV18-8C	054007-70246	22–18 AWG	8	100	5
RV18-8L	054007-70337	22–18 AWG	8	50	10
RV18-14C	054007-70248	22–18 AWG	1/4"	100	5
RV18-14L	054007-70339	22–18 AWG	1/4"	50	10
RV14-6C	054007-70241	16–14 AWG	6	100	5
RV14-6L	054007-70332	16–14 AWG	6	50	10
RV14-10C	054007-70243	16–14 AWG	10	100	5
RV14-10L	054007-70334	16–14 AWG	10	50	10
RV14-8C	054007-70242	16–14 AWG	8	100	5
RV14-8L	054007-70333	16–14 AWG	8	50	10
RV14-14C	054007-70244	16–14 AWG	1/4"	100	5
RV14-14L	054007-70335	16–14 AWG	1/4"	50	10
RV14-516L	054007-49560	16–14 AWG	5/16"	50	10
RV10-10L	054007-70329	12–10 AWG	10	50	5
RV10-10Q	054007-70477	12–10 AWG	10	25	10
RV10-6L	054007-49893	12–10 AWG	6	50	5
RV10-8L	054007-70328	12–10 AWG	8	50	5
RV10-8Q	054007-70476	12–10 AWG	8	25	10
RV10-14L	054007-70330	12–10 AWG	1/4"	50	5
RV10-14Q	054007-70478	12–10 AWG	1/4"	25	10
RV10-516Q	054007-49562	12–10 AWG	5/16"	25	10
RV10-38L	054007-70331	12–10 AWG	3/8"	50	5
RV10-38Q	054007-70479	12–10 AWG	3/8"	25	10