

ITT 3000 W 235 V-01Y0 Z/K

HALOTHERM | Infrared halogen lamps, quartz clear



Areas of application

- Plastics, paper and printing industries
- Drying paint and varnishes
- Coil coating
- Keeping food warm in restaurants

Product benefits

- Short response time
- High efficiency
- Precise controllability
- Long lamp life



Product datasheet

Technical data


Electrical data

Nominal wattage	3000.00 W
Nominal voltage	235 V
Nominal current	12.8 A
Lamp current	12.80000 A
Construction voltage	235 V

Photometrical data

Color temperature	2350 K
-------------------	--------

Dimensions & weight

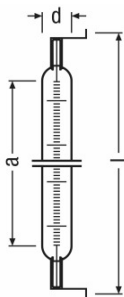

Diameter	12.0 mm
Length	361.0 mm
Filament length	280.00 mm

Lifespan

Lifespan	5000 h
----------	--------

Additional product data

Base (standard designation)	Y/Z
-----------------------------	-----

Capabilities

Burning position	Any
------------------	-----

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4008321206725	OSRITT3000Y0ZK	-	4739795	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321206725	ITT 3000 W 235 V- 01Y0 Z/K	Shipping carton box 30	165 mm x 360 mm x 515 mm	30.59 dm ³	2280.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.