


Application Scotch® Cloth Tapes

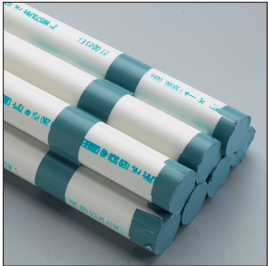

Application Scotch® Masking Tapes



Application Scotch® Finesline Tapes



Scotch® Masking Tapes / Finesline Tapes / Cloth Tapes

Selection Guide for AOEM



Important notice for purchasers :

All statements, technical information and recommendations contained in this brochure and its inserts are based on tests, and are believed to be accurate. Accuracy and completeness of information cannot be guaranteed, however, and you should ensure that the product is suitable for its intended application before use. All questions of liability relating to these products are governed by the terms of the sale subject, where applicable, to prevailing laws.



Tapes & Adhesives Group 3M UK Plc

3M Centre, Cain Road,
Bracknell, Berkshire.
RG12 8HT
Tel : 0870 6080 050
Fax : 0870 6070 099
website: www.mmm.com/uk/tag
E-mail: bondingsolutions.uk@mmm.com

Tapes & Adhesives Group 3M Ireland

Adelphi Centre,
Upper Georges Street,
Dun Laoghaire
Co. Dublin, Ireland
Tel : 01 280 3555
Fax : 01 280 3509

Scotch® Cloth Tapes



3903




3997



389

	Cloth Tapes		
Product	3903	3997	389
Temperature Performance [°C]	120	65	70
Total Thickness [mm]	0.160	0.220	0.260
Adhesion to Steel [N/100mm]	21	36	90
Tensile Strength [N/100mm]	245	356	800
Elongation at Break [%]	150	20	6
Backing	Cloth	Cloth	Cloth
Adhesive	Rubber	Rubber	Rubber
Tape Colour	7 different colours	black or silver	9 different colours
Typical Application	General Purpose	bundling, holding, splicing	bundling, holding, splicing
Roll Length [m]	50	50	50
Standard Width [mm]	19 / 25 / 38 / 50 / 75 / 100	25 / 38 / 50 / 100	19 / 25 / 38 / 50 / 75 / 100

Scotch® Masking Tapes

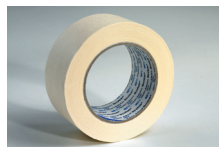

2214



2321



2364



2836



2610

Masking Tapes				
2214	2321	2364	2836	2610
60	80	100	140	160
0.135	0.135	0.160	0.170	0.175
26	26	44	44	52
350	352	400	460	440
10	10	10.5	10.5	10
Paper	Paper	Paper	Paper	Paper
Rubber	Rubber	Rubber	Rubber	Rubber
beige	beige	beige	beige	beige
Low bake	Low bake	Medium bake	High bake	High bake
50	50	50	50	50
19 / 25 / 30 / 38 / 50 / 75 / 100	19 / 25 / 30 / 38 / 50 / 75 / 100	19 / 25 / 30 / 38 / 50 / 75 / 100	19 / 25 / 30 / 38 / 50 / 75 / 100	19 / 25 / 30 / 38 / 50 / 75 / 100

Scotch® Fineline Tapes



471



218



222



4737

Fineline Tapes			
471	218	222	4737
70	120	160	160
0.130	0.120	0.060	0.130
28	44	26	16
264	228	456	244
130	490	130	150
PVC	PP	PET	PVC
Rubber	Rubber	Acrylic	Rubber
blue	green	white	light blue
Low bake	Medium bake	High bake	High bake
55	55	55	55
on request	on request	on request	on request