


Datasheet

Steel Zinc Plated Toggle Latch, Spring Loaded 45kgf Op. Tension

RS Stock number [197-4182](#)

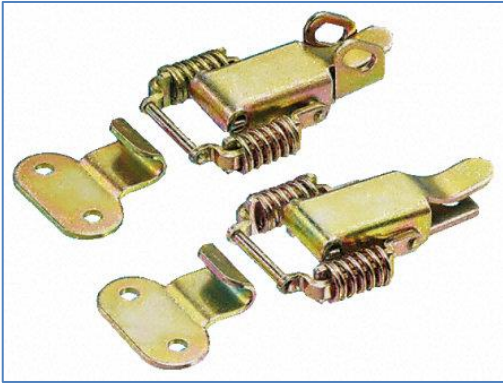

Description:

Available with or without padlock facility

Interchangeable with American models

Wide positioning tolerance created by spring mechanism

Failsafe design prevents over extension of links

Available in zinc passivated steel or A2 stainless steel

Suitable for screw fixing using 2xM5 screws for latch and 2xM5 screws for catch

Features:

- Dimensions 75 x 47 x 20mm
- Finish Zinc Plated
- Length 75mm
- Material Steel
- Operating Tension 45kgf
- Spring Loaded Yes

