


# Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
5	16	5	1,14	0,38	0,016	95000	60000	0,0050	625 *

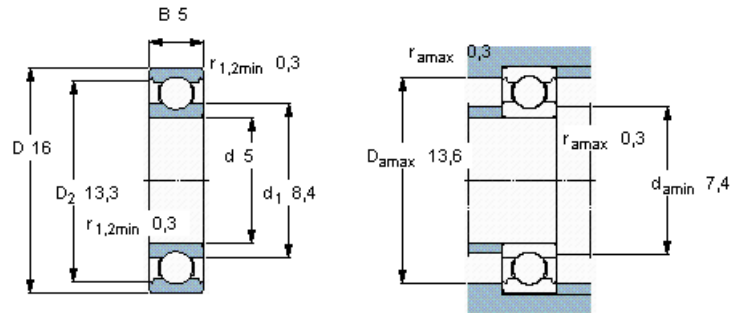

### Calculation factors

$k_r$  0,025  
 $f_0$  8,4