

## Mini-Lynx Ball

ML BALL 827 E14 9W SLV

0035404

### Range features



CE

### PRODUCT OVERVIEW

Ordering number	0035404
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	No
Cap/Base	E14
Type	BALL
EAN code	5410288354040
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Efficacy (Rated) (lm/w)	50
Watt (Nominal) (W)	9
Equivalent watt (W)	40
Voltage (V)	220-240

# Mini-Lynx Ball

ML BALL 827 E14 9W SLV

**0035404**

## DATA TABLE

### General data

Ordering number	0035404
Dry applications use only	Yes
Technology	Compact Fluorescent
Energy saving lamp	Yes
Energy class	A
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Lamp finish	Frosted
Lamp shape	Ball
Dimmable	No
Cap/Base	E14
Type	BALL
EAN code	5410288354040
E-number SE	8357579
Long description	
Product name	ML BALL 827 E14 9W SLV
Lamp mercury content (mg)	<2
Starting time (max) (s)	<1.5
Warm-up time to 60% of full light (max) (s)	<60
Control gear required	NO
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

### Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Lumen maintenance at end of nominal life (%)	60
Luminous flux (Nominal) (lm)	450

## Mini-Lynx Ball

ML BALL 827 E14 9W SLV

**0035404**

### Electrical data

<b>kWh per 1000 hours burning time</b>	9
<b>Efficacy (Rated) (lm/w)</b>	50
<b>Watt (Rated) (W)</b>	9
<b>Watt (Nominal) (W)</b>	9
<b>Equivalent watt (W)</b>	40
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	=0.55

### Physical data

<b>Weight (kg)</b>	0.05
<b>Lamp Length (mm) - C/L</b>	101.5±2
<b>Max. Lamp Diameter (mm) - D</b>	51±1
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	11.50 x 5.00 x 5.00
<b>Outer package dimensions (L x W x H) (cm)</b>	28.50 x 12.00 x 14.00


## Mini-Lynx Ball

ML BALL 827 E14 9W SLV

0035404

### TECHNICAL DRAWINGS

---

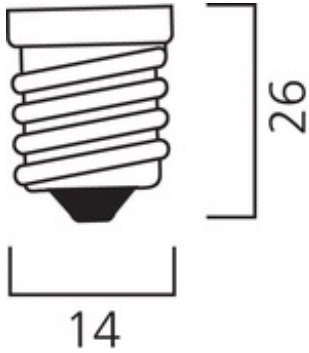

### ENERGY LABEL

---

