


RVVP

PVC Insulated PVC Sheathed Screened Soft Wire
铜芯聚氯乙烯绝缘聚氯乙烯护套屏蔽软电线

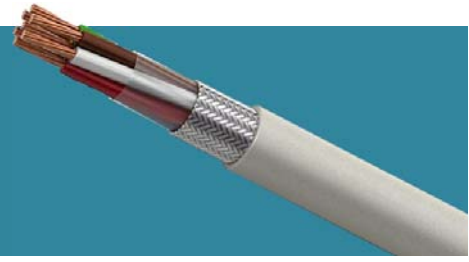

Application

- This product is fit for ac rated voltage 300/300V or below electric appliance, instruments and electro-equipments and automatic installations.

Construction

- Conductor: Flexible bare, annealed copper, acc to IEC60228 - 2004 class5
- Insulation: Polyvinyl chloride (PVC)
- Shielding: Copper wire braid
- Sheath: Polyvinyl chloride (PVC)
- Color: Black Grey or customer-specified

Technical Data

- Nominal voltage: 300 / 300V
- Temperature range : RVP 0°C~70°C/ RVP-90 0°C~ 90°C

Standards / Material properties

- Approvals: CCC; CE
- Application standards: JB/T 8734-1998; IEC 60227

Type selection

Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
1×0,3	0,5	0,4	3,5	14,46
1×0,4	0,5	0,4	3,7	16,44
1×0,5	0,5	0,4	3,8	17,99
1×0,75	0,5	0,4	4,1	21,50
1×1,0	0,6	0,6	4,9	30,25
1×1,5	0,6	0,6	5,2	36,64
1×1,25	0,7	0,6	6,0	55,92
*1×4	0,8	0,8	7,1	83,60
*1×6	0,8	0,8	8,2	107,54
2×0,3	0,5	0,6	6,2	40,16
2×0,4	0,5	0,6	6,6	45,19
2×0,5	0,5	0,6	6,8	19,05
2×0,75	0,5	0,6	7,4	57,68
2×1,0	0,6	0,6	8,2	71,22
2×1,5	0,6	0,8	9,2	92,90
*2×2,5	0,7	1,0	10,9	143,53

Dimensions and specifications may be changed without prior notice

应用

- 本产品适用于额定电压300/300V及以下电器、仪器、电子设备和自动化设施。

结构

- 导体：退火软铜线，符合IEC60228 -2004 五类导体
- 绝缘：聚氯乙烯
- 屏蔽：铜丝编织
- 护套：聚氯乙烯
- 颜色：黑灰或客户指定

技术参数

- 额定电压：300 / 300V
- 工作温度：RVP 0°C~70°C/ RVP-90 0°C~ 90°C


标准 / 材料性能

- 认证：CCC; CE
- 应用标准：JB/T 8734-1998; IEC 60227

RVVP

PVC Insulated PVC Sheathed Screened Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套屏蔽软电线

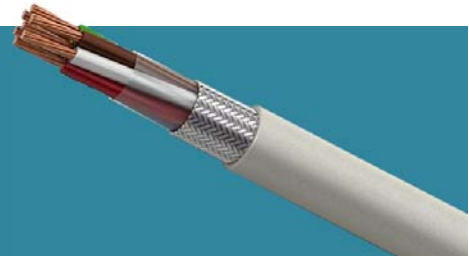

Type selection


Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
*2×4	0,8	1,0	11,5	188,1
3×0,3	0,5	0,6	6,5	46,65
3×0,4	0,5	0,6	6,9	53,15
3×0,5	0,5	0,6	7,1	28,20
3×0,75	0,5	0,6	7,8	69,62
3×1,0	0,6	0,8	9,1	93,67
3×1,5	0,6	0,8	10,0	122,92
*3×2,5	0,7	1,0	11,9	189,37
4×0,3	0,5	0,6	7,0	54,71
4×0,4	0,5	0,6	7,5	62,86
*4×0,5	0,5	0,8	8,2	74,85
*4×0,75	0,5	0,8	8,7	89,69
*4×1	0,6	0,8	9,7	113,06
*4×1,5	0,6	1,0	11,1	157,24
*4×2,5	0,7	1,0	12,8	231,10
5×0,3	0,5	0,6	7,6	63,28
5×0,4	0,5	0,6	8,1	73,13
*5×0,5	0,5	0,8	8,7	86,71
*5×0,75	0,5	0,8	9,4	104,44
*5×1	0,6	1,0	11,1	150,57
*5×1,5	0,6	1,0	11,9	183,97
*5×2,5	0,7	1,0	13,8	282,8
6×0,3	0,5	0,6	8,2	71,80
6×0,4	0,5	0,8	9,2	90,10
*6×0,5	0,5	0,8	9,3	99,40
*6×0,75	0,5	0,8	10	120,59
*6×1	0,6	1,0	11,8	171,85
*6×1,5	0,6	1,0	12,7	211,08
*6×2,5	0,7	1,0	14,8	315,00

Dimensions and specifications may be changed without prior notice

RVVP

PVC Insulated PVC Sheathed Screened Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套屏蔽软电线

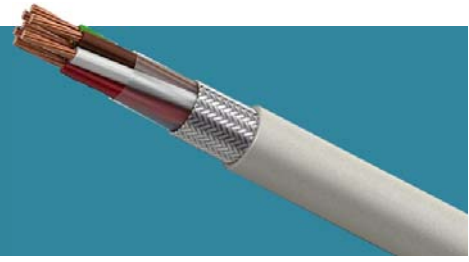

Type selection


Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
7×0,3	0,5	0,6	8,2	75,06
7×0,4	0,5	0,8	9,2	94,45
*7×0,5	0,5	0,8	9,3	104,62
*7×0,75	0,5	0,8	10	127,97
*7×1	0,6	1,0	11,8	181,80
*7×1,5	0,6	1,0	12,7	225,10
*7×2,5	0,7	1,0	14,8	338,10
8×0,3	0,5	0,6	8,7	85,02
8×0,4	0,5	0,8	9,6	106,81
*8×0,5	0,5	0,8	10,1	118,53
*8×0,75	0,5	0,8	1,8	145,43
*8×1	0,6	1,2	13,2	216,27
*8×1,5	0,6	1,2	14,2	266,95
*8×2,5	0,7	1,2	16,4	400,23
10×0,3	0,5	0,8	10,9	120,78
10×0,4	0,5	0,8	11,6	139,95
*10×0,5	0,5	1,0	12,4	164,19
*10×0,75	0,5	1,0	13,2	199,21
*10×1	0,6	1,2	15,1	262,76
12×0,3	0,5	0,8	11,2	133,30
12×0,4	0,5	0,8	11,9	156,51
*12×0,5	0,5	1,0	12,7	183,47
*12×0,75	0,5	1,0	13,5	224,30
*12×1	0,6	1,2	15,5	296,37
14×0,3	0,5	0,8	11,7	148,40
14×0,4	0,5	0,8	12,5	173,78
*14×0,5	0,5	1,0	13,3	203,67
*14×0,75	0,5	1,0	14,2	250,38
*14×1	0,6	1,2	16,2	331,31

Dimensions and specifications may be changed without prior notice

RVVP

PVC Insulated PVC Sheathed Screened Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套屏蔽软电线

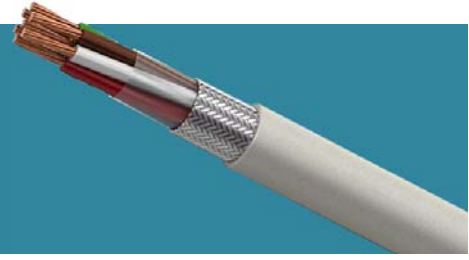

Type selection

Cores×cross-sec	Insulation Thickness	Sheath Thickness	Outerø	Weight
Nr×mm ²	mm	mm	ca,mm	ca,kg/km
16×0,3	0,5	0,8	12,3	162,94
16×0,4	0,5	0,8	13,1	191,47
*16×0,5	0,5	1,0	14,0	224,35
*16×0,75	0,5	1,0	14,9	276,99
*16×1	0,6	1,2	17,1	366,94
19×0,3	0,5	0,8	12,9	181,16
19×0,4	0,5	1,0	14,2	224,46
*19×0,5	0,5	1,2	15,1	262,07
*19×0,75	0,5	1,2	16,1	323,75
*19×1	0,6	1,2	17,9	413,35
24×0,3	0,5	1,0	14,4	232,09
24×0,4	0,5	1,0	16,4	273,80
*24×0,5	0,5	1,2	17,4	319,65
*24×0,75	0,5	1,2	18,6	396,78
*24×1	0,6	1,2	21,0	508,49

Dimensions and specifications may be changed without prior notice