



ENGLISH


Datasheet

AC Axial Fan, 120 x 120 x 38mm, 187m³/h, 23W, 230 V ac (OA4715 Series)

RS Stock 619-6961



Dimensions: (mm)

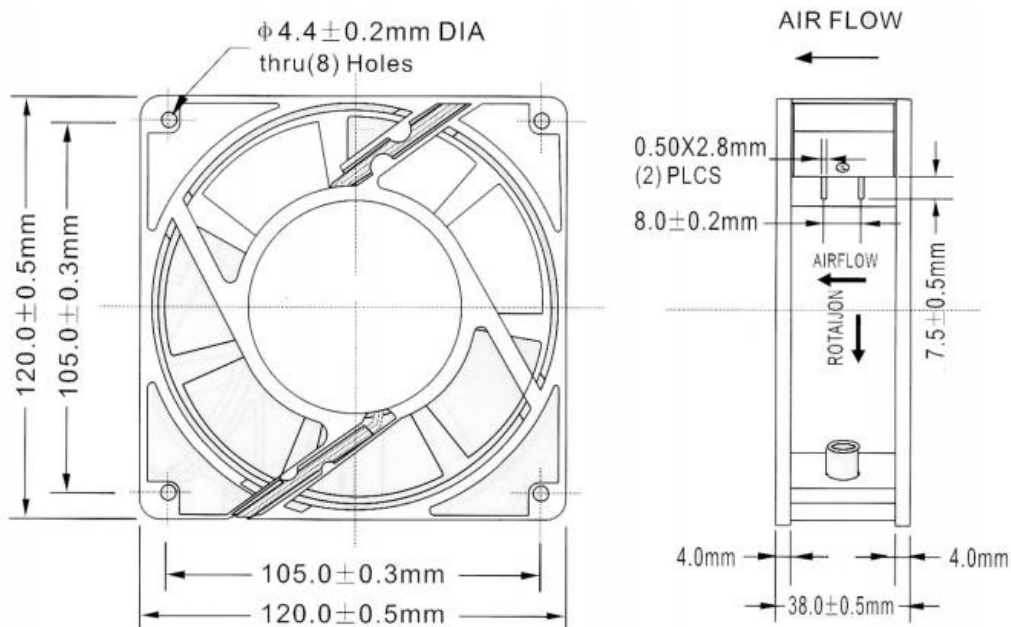



Specifications

- Frame: Die cast Aluminium
- Impeller: PBT , UL94V-0 Thermoplastic

- Motor: Shaded Pole
- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-20C ~ +80C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage	Current	Connection Type
6196955	OA4715-12-1TB	3000	105	43	120	80~130	20	Wire
6196961	OA4715-23-1TB	3000	105	43	230	160~260	20	Wire