
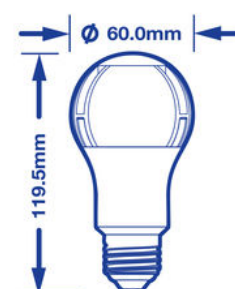


## Verbatim LED Classic A E27 14W 2700K 1000lm 2700K Warm White 1000 LM DIM


- E27 Socket
- 220 - 240 Voltage
- 30,000 hours Lifetime
- Dimmable
- 80% Energy Saving
- Lumen: 1000
- Equivalent to 71W incandescent bulb

Product Number	52244
<b>General Data</b>	
Lamp Socket	E27
<b>Electric Data</b>	
Wattage (W)	14
Wattage Equivalent (W)	71
Voltage (V)	220 - 240
Dimmable	yes
Power Factor	0.80
Operating Frequency (Hz)	50-60
<b>Geometric Data</b>	
Length (mm)	119.5
Diameter (in mm)	60
Weight (g)	180
<b>Photometric Data</b>	
Luminous Flux (lm)	1000
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	270
Luminous Efficacy (lm/W)	71
Lifetime (hrs)	30,000
Switching Cycle	20,000

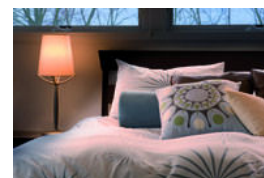

02/07/2014

## Energy Rating

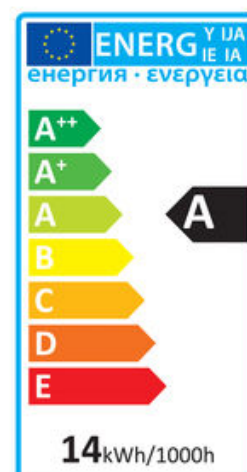

## Technical Packaging Details

**Barcode**

023942522447

**EAN 128**

(02)00023942522447(37)10(91)807

**EAN 14**

50023942522442

**Pack Dimensions(HxWxL)**

H 133 x W 64 x L 64

**Pack Weight**

220

**MOQ**

4

**Carton Dimensions (HxWxL)**

H 75 x W 160 x L 280

**Cartons/Pallet**

260

**Layers/Pallet**

13

**Units/Pallet**

1040

02/07/2014