

64337 A 48-15

Halogen lamps with reflector, current-controlled, 45...48 W



Product features

- Dimmable
- Available with connector combinations A, B, C/Z on request
- Infrared radiation output that provides light in the worst of conditions

Technical data

Electrical data


Nominal wattage	48 W
Nominal current	6.60 A

Light technical data

Axial luminous intensity	23000 cd
Luminous intensity	20000 cd

Dimensions & weight

Diameter	50.4 mm
Length with base excl. base pins/connection	45.00 mm
Length	46.0 mm

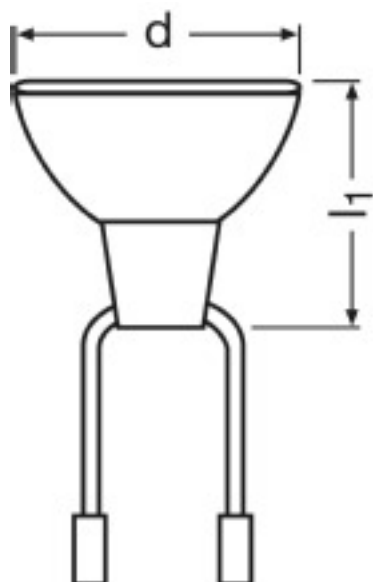

Product line drawing with letters

Lifespan

Lifespan	1500 h
-----------------	--------

Country specific categorizations

Order reference	64337
------------------------	-------

Safety advice

To prevent personal injury or damage to property, halogen lamps may only be operated in suitable luminaires designed with suitable mechanisms (protective shields, grids, etc.) to ensure that in the event of a lamp bursting no parts/shards can escape and that during operation no ultraviolet radiation can escape. There must also be a warning sign to indicate that the lamps give off high levels of heat. Detailed information is available on request.



Burning position

Logistical Data

Product code	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Gross weight	Volume
4008321102737	Folding carton box 1	50 mm x 50 mm x 63 mm	38.34 g	0.16 dm ³
4008321102744	Shipping carton box 20	109 mm x 131 mm x 257 mm	856.80 g	3.67 dm ³

References / Links

For more information on airfield lamps see the brochure:

"The reliable guiding stars - Effective solutions for airfield lighting: Tungsten halogen lamps and LED light sources".

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.