

EINZELAUFSTELLUNGSTRAEGER FUER
3RU21/3RB30/3RB31 BGR S0 EINZELAUFSTELLUNG
HAUPTSTROMKR.: FEDERZUGKL. HILFSSTROMKR.: --

General technical data:

Product brand name		SIRIUS
Product designation		individual mount
Size of overload relay		S0
Ambient temperature		
• during storage	°C	-55 ... 80
• during the operating phase	°C	-20 ... 70

Installation/mounting/dimensions:

Type of fixing/fixation		screw and snap-on mounting onto 35 mm standard mounting rail
Width	mm	45
Height	mm	114
Depth	mm	76

Connections:

design of the electrical connection		
• for main current circuit		spring-loaded terminals
Type of the connectable conductor cross-section		
• for main contacts		
• unifilar		1 ... 10 mm ²
• stranded wire		1 ... 10 mm ²
• stranded wire		
• with conductor end processing		1 ... 6 mm ²
• without conductor final cutting		1x (1 ... 6 mm ²)
• at AWG-conductors		
• for main contacts		1x (16 ... 8)




Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Global Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

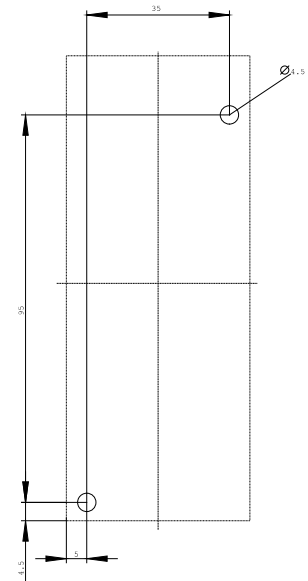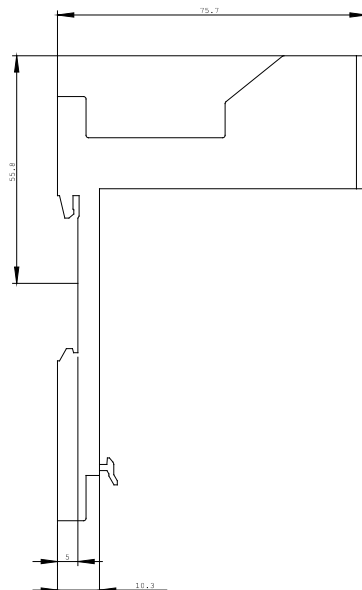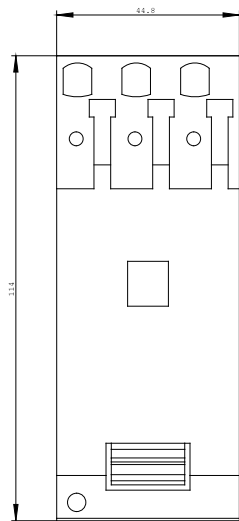

last change:

Apr 26, 2010