 

 

 

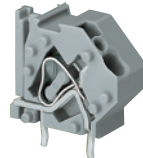
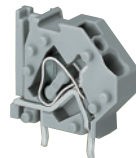
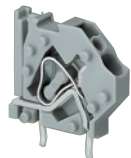











 
 
 



Modular Terminal Blocks 4 mm²/AWG 12, Series 745, Pin Spacings 5 mm / 0.197 in, 7.5 mm / 0.295 in, 10 mm / 0.394 in

Pin spacing 5 mm / 0.197 in 0.08 – 4 mm ² AWG 28 – 12 250 V/4 kV/3 300 V, 20 A 20 A  8 – 9 mm / 0.33 in *  ENEC	Pin spacing 7.5 mm / 0.295 in 0.08 – 4 mm ² AWG 28 – 12 500 V/6 kV/3 300 V, 20 A 20 A  8 – 9 mm / 0.33 in *  ENEC	Pin spacing 10 mm / 0.394 in 0.08 – 4 mm ² AWG 28 – 12 630 V/8 kV/3 300 V, 20 A 20 A  8 – 9 mm / 0.33 in *  ENEC
--	--	---

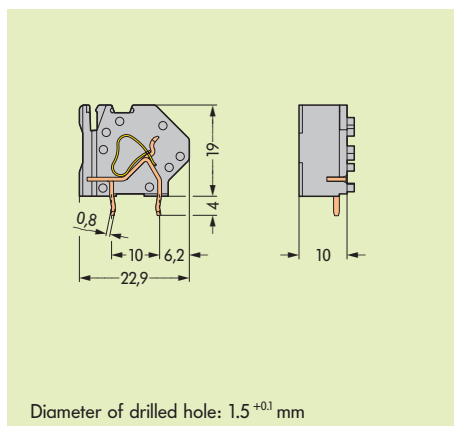
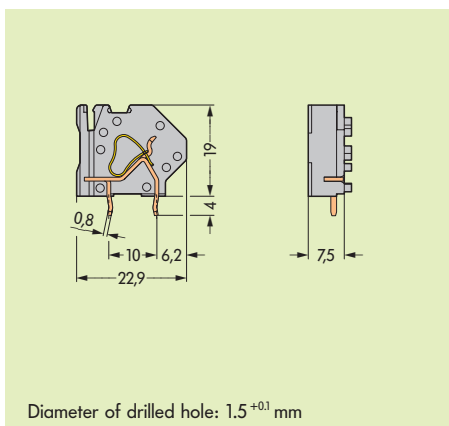
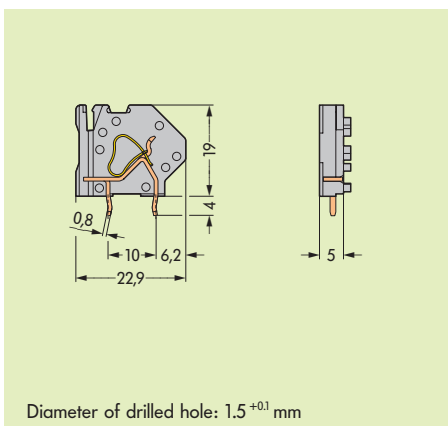


Color	Item No.	Pack.-unit pcs	Color	Item No.	Pack.-unit pcs	Color	Item No.	Pack.-unit pcs
Modular terminal blocks, 2 solder pins/pole			Modular terminal blocks, 2 solder pins/pole			Modular terminal blocks, 2 solder pins/pole		
grey	745-801	200 (2 x 100)	grey	745-811	200 (2 x 100)	grey	745-821	200 (2 x 100)
light grey	745-803	200 (2 x 100)	light grey	745-813	200 (2 x 100)	light grey	745-823	200 (2 x 100)
blue	745-804	200 (2 x 100)	blue	745-814	200 (2 x 100)	blue	745-824	200 (2 x 100)
green-yellow	745-807	200 (2 x 100)	green-yellow	745-817	200 (2 x 100)	green-yellow	745-827	200 (2 x 100)
light green	745-808	200 (2 x 100)	light green	745-818	200 (2 x 100)	light green	745-828	200 (2 x 100)
			① suitable for Ex i applications			① suitable for Ex i applications		

Accessories (for WMB marking accessories and miniature WSB marking accessories see section 11)

	End plate, snap-on type 1.5 mm/0.059 in thick grey 745-100 100		End plate, snap-on type 1.5 mm/0.059 in thick grey 745-100 100		End plate, snap-on type 1.5 mm/0.059 in thick grey 745-100 100
	End plate with fixing flange, grey 745-140 100		End plate with fixing flange, grey 745-140 100		End plate with fixing flange, grey 745-140 100
	End plate with fixing flange, grey 745-145 100		End plate with fixing flange, grey 745-145 100		End plate with fixing flange, grey 745-145 100
	Test plug, w. cable 500 mm/1'7.7" 2 mm/0.079 in Ø, red 210-136 50 2.3 mm/0.091 in Ø, yel. 210-137 50		Test plug, w. cable 500 mm/1'7.7" 2 mm/0.079 in Ø, red 210-136 50 2.3 mm/0.091 in Ø, yel. 210-137 50		Test plug, w. cable 500 mm/1'7.7" 2 mm/0.079 in Ø, red 210-136 50 2.3 mm/0.091 in Ø, yel. 210-137 50
	Comb type jumper bar 1 to 3 745-181 250 (5 x 50) 2-way 745-182 250 (5 x 50) 3-way 745-183 250 (5 x 50) 4-way 745-184 200 (4 x 50) 5-way 745-185 200 (4 x 50) 10-way 745-180 200 (4 x 50)		Comb type jumper bar 1 to 3 745-191 250 (5 x 50) 2-way 745-192 250 (5 x 50) 3-way 745-193 250 (5 x 50) 4-way 745-194 200 (4 x 50) 5-way 745-195 200 (4 x 50) 10-way 745-190 200 (4 x 50)		Comb type jumper bar 1 to 3 745-281 250 (5 x 50) 2-way 745-282 250 (5 x 50) 3-way 745-283 250 (5 x 50) 4-way 745-284 200 (4 x 50) 5-way 745-285 200 (4 x 50) 10-way 745-280 200 (4 x 50)

Dimensions (in mm)



* Approvals with corresponding ratings see pages 12.3 ff.