
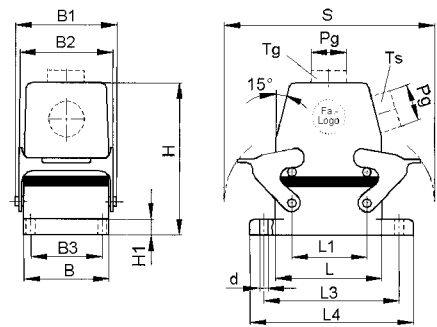


3.3 EPIC® Eco H - B

Eco Set / Eco Set / Eco Set

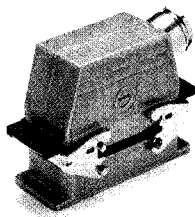

EPIC® Eco Set: Tülle/Anbaugehäuse (Kabeleingang seitlich, Querbügel, Kabelverschraubung)
EPIC® Eco Set: hood/panel mount base (side entry, double locking lever, cable gland)
EPIC® Eco Set: capot/embase encastrée (sortie latérale, double levier, presse-étoupe)

H-B 16

Artikel part article	Art.Nr. part No. N° art.	PG	L	L1	L2	L3	L4	B	B1	B2	B3	B4	B5	H	H1	H2	S	d
H-B 16 TS / H-B 16 AG	70365000*	21	93,3	47,5		103	113	43	57,8	53	32			88,8	4		136,5	4,3
H-B 16 TS / H-B 16 AG	70365200*	29																

Einsätze / Inserts / Inserts: 1.3: H-BE 16 / 1.4: H-BS 6 / 1.5: H-BVE 6 / 1.6: H-D 40 / 1.7: H-DD 72 / 1.8: MC 16 / 1.9: TB-H-BE 16, TB-H-D 40
Deckel / Cover / Couvercle: 5.1: H-B 16

H-B 24

Artikel part article	Art.Nr. part No. N° art.	PG	L	L1	L2	L3	L4	B	B1	B2	B3	B4	B5	H	H1	H2	S	d
H-B 24 TS / H-B 24 AG	70367000*	21	120	74		130	140	43	57,8	53	32			88,8	4		163	4,3
H-B 24 TS / H-B 24 AG	70367200*	29																

Einsätze / Inserts / Inserts: 1.3: H-BE 24 / 1.5: H-BVE 10 / 1.6: H-D 64 / 1.7: H-DD 108 / 1.8: MC 24 / 1.9: TB-H-BE 24, TB-H-D 64
Deckel / Cover / Couvercle: 5.1: H-B 24

Jetzt neu !

H-B 6 - H-B 24
Anbau-/Tüllengehäuse als Einzelkomponenten
in EPIC® Eco Version

New !

H-B 6 - H-B 24 panel mount base/hood as separat
components in version Epic® Eco.

Nouveauté !

Dans la version EPIC® Eco sont maintenant
disponibles les embases et les capots séparément.