



CONTACTOR COMBIN. TO REVERS. 30 KW,
SIZE S3, 110 V AC 50 HZ / 120 V AC 60 HZ

General details:

Product function		reversing contactor
Size of the contactor		S3
Width	mm	150
Height	mm	169
Depth	mm	139
Item designation		
<ul style="list-style-type: none"> • according to DIN EN 61346-2 		Q
<ul style="list-style-type: none"> • according to DIN 40719 extendable after IEC 204-2 / according to IEC 750 		K

Control circuit:

Type of voltage / of the controlled supply voltage		AC
Control supply voltage / 1		
<ul style="list-style-type: none"> • at 50 Hz / for AC <ul style="list-style-type: none"> • rated value 	V	120
<ul style="list-style-type: none"> • at 60 Hz / for AC <ul style="list-style-type: none"> • rated value 	V	120
Control supply voltage frequency		
<ul style="list-style-type: none"> • 1 / rated value 	Hz	60
<ul style="list-style-type: none"> • 2 / rated value 	Hz	60

Main circuit:

Operating current / at AC-3 / at 400 V		
• rated value	A	65
Service power / at AC-3 / at 400 V		
• rated value	kW	30

Auxiliary circuit:

Number of NC contacts / for auxiliary contacts / per direction of rotation		0
Number of NO contacts / for auxiliary contacts / per direction of rotation		0

Connection type:

Design of the electrical connection / for main current circuit		screw-type terminals
Type of mounting		screw and snap-on mounting onto 35 mm standard mounting rail according to DIN EN 50022

Ambient conditions:

Ambient temperature		
• during operating	°C	-25 ... +60
Protection class IP / on the front		IP20

Certificates/approvals:

General Product Approval



Declaration of Conformity

Shipping Approval



Shipping Approval other



[Confirmation](#)

[other](#)



Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)


<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

CAX-Online-Generator

<http://www.siemens.com/cax>

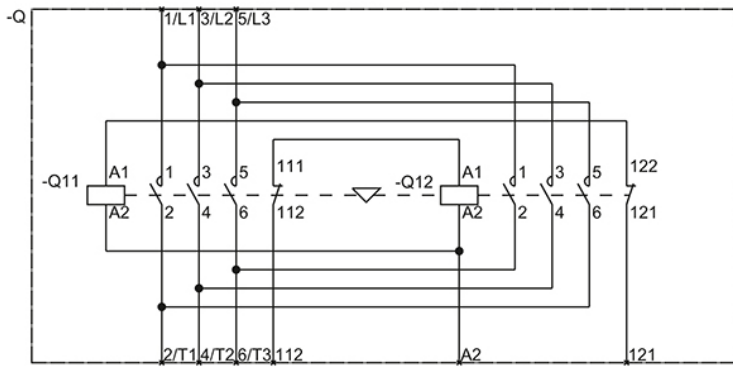

last change:

Apr 13, 2012