

# 25 01 160


## Snipe Nose Side Cutting Pliers (Radio Pliers)



- Suitable for finer gripping and cutting work
- Half-round, long, tapered jaws
- Knurled gripping surfaces
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction hardened, cutting edge hardness approx. 61 HRC
- Vanadium electric steel, forged, multi stage oil-hardened



Article No.	25 01 160
EAN	4003773010845
Head	polished
Handles	plastic coated
Style	0
Pliers	black atramentized
Cutting capacities medium hard wire (diameter) Ø mm	2,5
Cutting capacities hard wire (diameter) Ø mm	1,6
T1 mm	9,0
W3 mm	16,5
W4 mm	3,0
T2 mm	2,5
L3 mm	50,0
Length mm	160
Net weight g	113

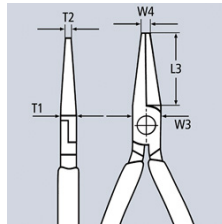

technical change and errors excepted

