


Anschlußmaße nach IEC 169-16 / mating face according to IEC 169-16

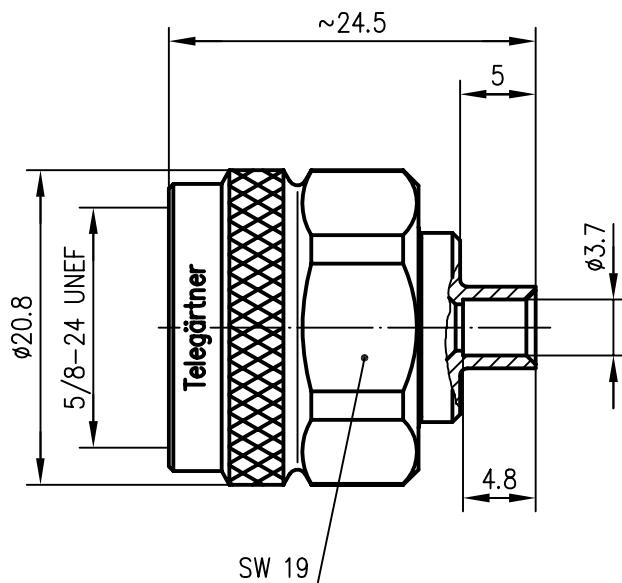

Innenleiter / inner conductor

CuZn39Pb3

Cu2Ag5

sonstige Metallteile / other metal parts

CuZn39Pb3

CuSnZn3

Isolierung / insulator

PTFE

Dichtung / gasket

Silikon

Kabel / cable

G10: 1673A Belden, EZ 141 Suhner, RG-402/U,
Sucoform 141 Suhner, UT-141

 
Montage / assembly

B71

a	Frequency Frequenz /	VSWR IEC 169-16	VSWR typ.
	1.0 GHz	1.06	1.020
	2.0 GHz		1.036
	6.0 GHz		1.064
	11.0 GHz	1.30	1.118

Einfügedämpfung / insertion loss

≤0.1 dB bis/up to 4 GHz

a	13220	27.02.02	HM	2000	Datum/date	Name/name	Werkstoff/ material	
				gez./drawn	26.09.	HM		
				gepr./appr.	09.10.00	GJ	Oberfläche/ finish	
				Norm/stand.				
				Maßstab/scale	Benennung/title			 Telegärtner
2:1	N-Kabelstecker N Straight Plug							
untol. Maße/ dim. without tolerances according to	Unterl./doc.type	Zeichnungsnr./drawing no.		 Maße/dimensions: mm				
	K	J01020A0109						
Änd./rev. Index	Änderungsmittelteilung/ revision code	Datum/ date	Name/ name	Ersatz für/ replaces	J01020B0043			Original: DIN A4