



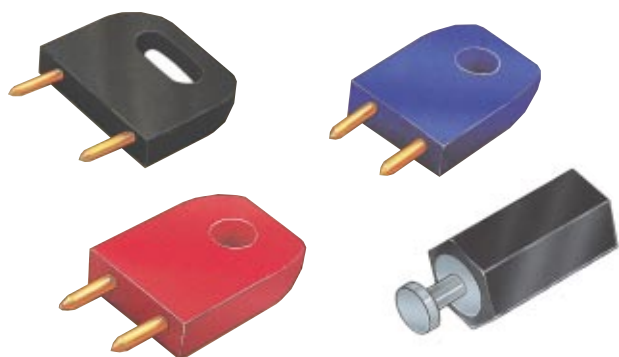


INSULATED PLUGS/INSULATORS

1MM INSULATED AND UNINSULATED PLUGS

Style 1

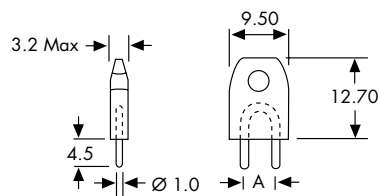


Style 2

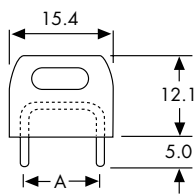

Precision 1mm diameter brass shorting plugs moulded into polyacetal thermoplastic insulators. Choice of colour. Can be used with any 1mm socket. Uninsulated plugs may be soldered directly into PC board for permanent linking.

 Plating finish: Gold (-05), Tin (-01)
Current rating: 10A at 20°C




Colour	Order Code (Gold)			
Red	D3086-99	D3087-99	D3088-99	D3089-99
Black	D3086-98	D3087-98	D3088-98	D3089-98
Blue	D3086-97	D3087-97	D3088-97	D3089-97
Style	1	1	2	2
Dim A	5.08	6.35	10.16	12.70

Order Code	D3080-01 D3080-05	D3081-01 D3081-05	D3082-01 D3082-05
A	5.08	6.35	10.16
B	9.00	9.00	9.00


INSULATORS

- Body: High temperature thermoplastic.
- Terminal: Brass (90/10 tin/lead plated).
- Threaded insert: Brass (nickel plated).

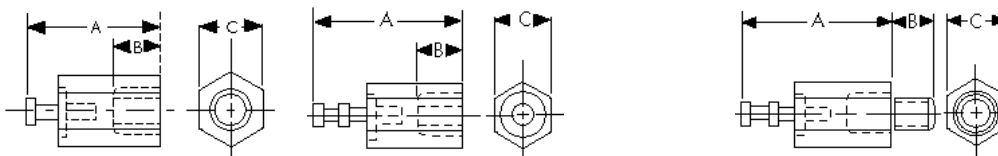

Order Code	W2330-00	W2331-00	W2232-00	W2332-00
A	15.10	19.10	11.10	19.10
B	3.20	3.20	3.20	6.35
C	6.35	6.35	3.90	6.35
Thread	M3	M3	M2	M3
Current Rating	10A at 5kv	10A at 5kv	5A at 2kv	10A at 5kv
Test Voltage kv	10	10	5	10

Assembled
dims.

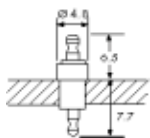

Current rating: 5A
Test voltage: 5kV
Max. temp. rating: 200°C
Mounting hole: 3.96
Panel thickness: 0.72 to 1.6

P.T.F.E. FEED THROUGH TERMINAL ORDER CODE W2222-00

Silver plated brass terminal supplied partially assembled with a P.T.F.E. insulating bush. Interference fit with panel when fully assembled.