


Protective covers - VS-SCRJ-PC - 1653757

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

IP67 protective cover, for covering the male inserts in the sleeve housings IP67, VS-SCRJ-..., VS-04-..., VS-06-... and VS-08-...



Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 017918 970130
Weight per Piece (excluding packing)	4.09 g
Custom tariff number	39269097
Country of origin	Switzerland

Technical data

Mechanical characteristics

Connection profile	SCRJ
Locking type	Without
Color	gray

Ambient conditions

Ambient temperature (operation)	-40 °C ... 80 °C
Degree of protection	IP67

Material data

Inflammability class according to UL 94	V0
Housing material	PA
Material	Plastic

Classifications

eCl@ss

eCl@ss 4.0	27140816
------------	----------

Protective covers - VS-SCRJ-PC - 1653757

Classifications

eCl@ss

eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260705
eCl@ss 7.0	27440309
eCl@ss 8.0	27440309

ETIM


ETIM 2.0	EC000764
ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002641

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Drawings

Dimensioned drawing

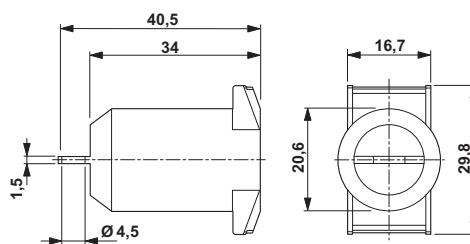

Protective cover, IP67