



CorePro LEDtube

CorePro LEDtube 1200mm 20W 840 C

The CorePro LEDtube is an affordable LED solution suitable for replacing T8 fluorescent lamps. The product provides a natural lighting effect for use in general lighting applications, as well as instant energy savings – an environmentally friendly solution.

Product data

• General Characteristics

Main Application	Industrial
Cap-Base	G13
Rated Lifetime	30000 hr
Nominal Lifetime hours	30000 hr

• Light Technical Characteristics

Colour Code	840
Beam Angle	150 D
Correlated Colour Temperature	4000 K
Colour rendering index	80
Rated Luminous Flux	1600 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	<6
Rated Beam Angle	150 D

• Electrical Characteristics

Wattage	20 W
Voltage	220-240 V
Line Frequency	50/60 Hz
Power Factor	0.9 (min) -
Dimmable	No
Rated Wattage	20 W
Starting Time	0.5 (max) s
Warm-up Time to 60% Light Outp	instant full light
Energy saving product	Yes
Suitable for accent lighting	No

• Temperature Characteristics

T-case maximum	55 (max) C
Operating temperature	-30 (min), 45 (max) C
T-Storage	-40 (min), 65 (max) C

• Environmental characteristics

Energy Efficiency Label (EEL)	A
Energy consumption kWh/1000h	20 kWh

• Measuring Conditions

Switching cycle	50000X
-----------------	--------

• Product Dimensions

Length A1	1198.0 mm
Fixing Hole Distance A2 Length	1205.0 mm
Length A3	1212.0 mm
Mounting hole diameter	25.68 mm
Circular outline dimension	28 mm

• Approval & Application Chars

VDE marking	No
CE marking	Yes
UL certificate	No
RoHS compliance	Yes



PHILIPS

CorePro LEDtube


KEMA Keur certifi-
cate Yes

• Product Data

Order code 669678 00
Full product code 871829166967800
Full product name CorePro LEDtube 1200mm 20W 840 C
Order product name CorePro LEDtube 1200mm 20W 840 C

Pieces per pack 1
Packing configuration 10
Packs per outerbox 10
Bar code on pack - EAN1 8718291669678
Bar code on outerbox - EAN3 8718291669685
Logistic code(s) - 12NC 929000296632
Net weight per piece 0.270 kg

Dimensional drawing

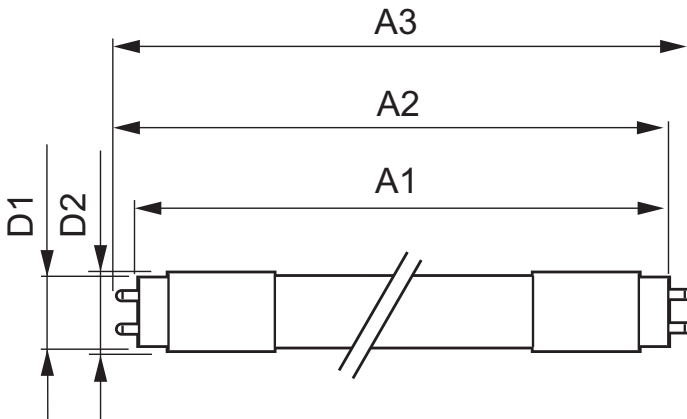

CorePro LEDtube 1200mm 20W 840 C

Product	A1 (Norm)	A2 (Norm)	A3 (Norm)	D1 (Norm)	D2 (Norm)
TLED 1200mm 20W840 T8	1198.0	1205.0	1212.0	25.68	28



G13



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, December 23
data subject to change