



ENGLISH

Datasheet

## RS Pro Rectangular 200V, 0.5 A Reed Switch

RS Stock No: **361-4911**



### Product Details


RS Pro rectangular reed switch has a current rating of 0.5 A and voltage rating of 200 V. It measures 32 x 8 x 15 mm. This proximity switch is used in position and limit sensing, linear actuators, security system switch and door switch.

### Features and Benefits

- Aluminium housings with fixing holes
- Fully encapsulated to IP67
- Dimensions: 32 x 15 x 8 mm

**Specifications:**

Contact Position	NO
Contact Resistance	300 mΩ
Depth	8 mm
Dimensions	32 x 15 x 8 mm
Length	32 mm
Maximum AC Voltage	200 V ac
Maximum Current	0.5 A
Maximum Operating Temperature	+85°C
Minimum Operating Temperature	-20°C
Normal State Configuration	NO
Switch Shape	Rectangular
Switch Type	Proximity
Total Length	32 mm
Width	15 mm
Application	Position Sensing, Linear Actuators, Security Switching, Door Switch
Material	Aluminium (Case), PVC (Cable)
Switching Distance	10.0 mm Min.

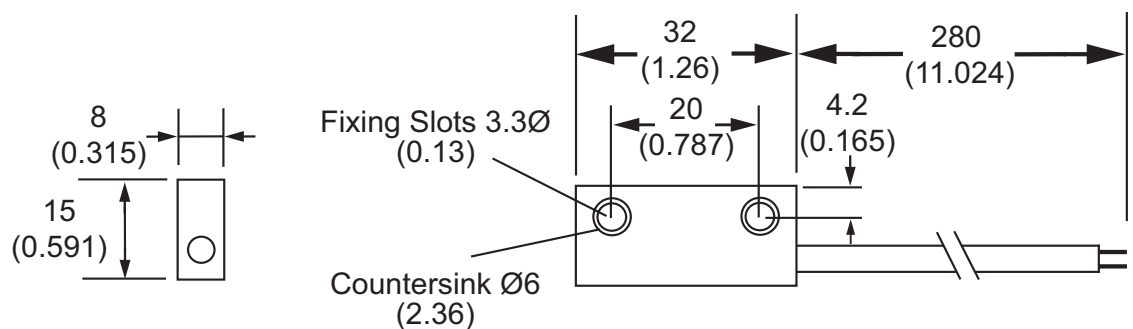

Drawings not to scale  
All dimensions in mm nominal