

ToLEDo G9/G4/Pygmy

ToLEDo G9 1.5W 80LM 827 SL

0126730



Range features

- Up to 80% energy saving compared to halogen lamps
- 100% retrofit - compact size for existing fittings
- Uniform light distribution
- Available in Homelight (2700K) and Warm White (3000K)
- Average rated life up to 25,000 hrs



PRODUCT OVERVIEW

Ordering number	0126730
Technology	LED
Light colour	827 Homelight
Energy class	A+
Average life (Rated) (h)	25000
Lamp shape	Capsule
Lamp finish	frosted
Dimmable	No
Cap/Base	G9
Type	ToLEDo Pygmy/ G9/ G4
EAN code	5410288267302
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	80
Efficacy (Rated) (lm/w)	53
Watt (Nominal) (W)	1.5
Equivalent watt (W)	10
Voltage (V)	220-240

ToLEDo G9/G4/Pygmy

ToLEDo G9 1.5W 80LM 827 SL

0126730

DATA TABLE

General data

Ordering number	0126730
Dry applications use only	Yes
Technology	LED
Energy saving lamp	Yes
Average life (Nominal) (h)	25000
Energy class	A+
Average life (Rated) (h)	25000
Lamp shape	Capsule
Lamp finish	frosted
Dimmable	No
Cap/Base	G9
Type	ToLEDo Pygmy/ G9/ G4
EAN code	5410288267302
E-number FI	4740220
Long description	Up to 80% energy saving compared to halogen lamps. 100% retrofit - compact size for existing fittings. Uniform light distribution. Available in Homelight (2700K) and Warm White (3000K). Average rated life up to 25,000 hrs
Product name	ToLEDo G9 1.5W 80LM 827 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Fixture rating	Open
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	>12500
Special purpose lamp	No
Transformer required	No
Sales pack quantity	6
Optimal operating condition (°C)	25

ToLEDo G9/G4/Pygmy

ToLEDo G9 1.5W 80LM 827 SL

0126730

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Suitable for accent lighting	No
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	80
Luminous flux (Nominal) (lm)	80
Lumen maintenance at end of nominal life (%)	70
Chromaticity coordinate Y	-1
Chromaticity coordinate X	-1
Adjustable chromaticity	No

Electrical data

kWh per 1000 hours burning time	2
Efficacy (Rated) (lm/w)	53
Watt (Rated) (W)	1.5
Watt (Nominal) (W)	1.5
Equivalent watt (W)	10
Voltage (V)	220-240
Lamp power factor	0.8

Physical data

Weight (kg)	0.01
Lamp Length (mm) - C/L	47
Max. Lamp Diameter (mm) - D	14
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	4.80 x 4.80 x 4.40
Inner package dimensions (L x W x H) (cm)	19.40 x 14.10 x 7.90
Inner package net weight (kg)	0.07
Outer package dimensions (L x W x H) (cm)	74.50 x 21.00 x 19.00

ToLEDo G9/G4/Pygmy



ToLEDo G9 1.5W 80LM 827 SL

0126730

TECHNICAL DRAWINGS

Dimensions (mm)

G9	0126730
H	47+-1
W	13.8+-0.5

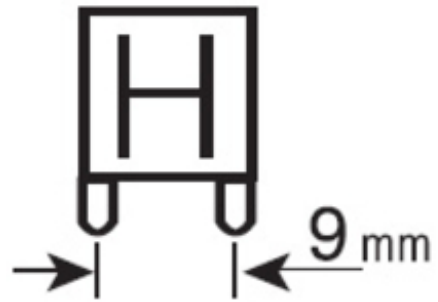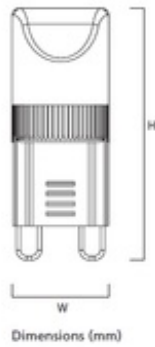

ENERGY LABEL

□