

M 237-V0



Euromas
Enclosures, polycarbonate V0

Order no.: 02237094

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

Protection class


Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.

Enclosure material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: V0 = version in UL 94 V0 enclosure material.
IP = Ingress protection acc. to DIN EN 60529

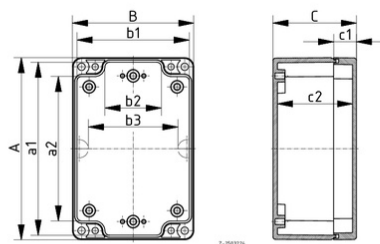

A	200 mm
B	120 mm
C	90 mm
a1	193 mm
a2	174,2 mm
b1	113 mm
b2	74,2 mm
c1	30 mm
c2	83,5 mm

Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[02237094_M-237-V0-G.dxf](#) (338 KB)

Catalogue drawing in PDF format:

[02237094_M-237-V0.pdf](#) (96 KB)

Chapter download

[Euromas_ABS_PC_GB.pdf](#) (338 KB)

Accessories



Mounting plates, laminated paper (Pertinax), galvanised steel for version 260

22000700

[M](#)

For EM/ET 221, EM/ET 237, M/T 221, M/T 237



Rubber feet, plug-in

22003300

[E](#)

For M/T 208-260



Silicone seal for lid

22003900

[SIL](#)

For M/T 221, M/T 237



Wall brackets on rear, screw-on, polycarbonate

22004900

[WL](#)

For M/T 210-243, M/T 246-253



DIN rails DIN EN 60715 TH 15

22002100

[TS 15](#)

For M/T 221-223, M/T 237



DIN rails DIN EN 60715 G 32

22002110

[TS 32](#)

For M/T 221-223, M/T 237



DIN rails DIN EN 60715 TH 35

22002115

[TS 35](#)

For M/T 221-223, M/T 237



Threaded inserts for mounting bosses

59002810	DODGE M3x6,5	ND = 4.0 x 6.5
59002820	DODGE M4x9,5	ND = 5.4 x 9.5



Set of hinges

22006000	SchM
----------	----------------------

* = Available on request