



Datasheet


ENGLISH

AC Axial Fan, 172 Dia. x 51mm, 399.5m³/h, 35W, 230 V ac (OA172S Series)

RS Stock 619-6876



Dimensions: (mm)

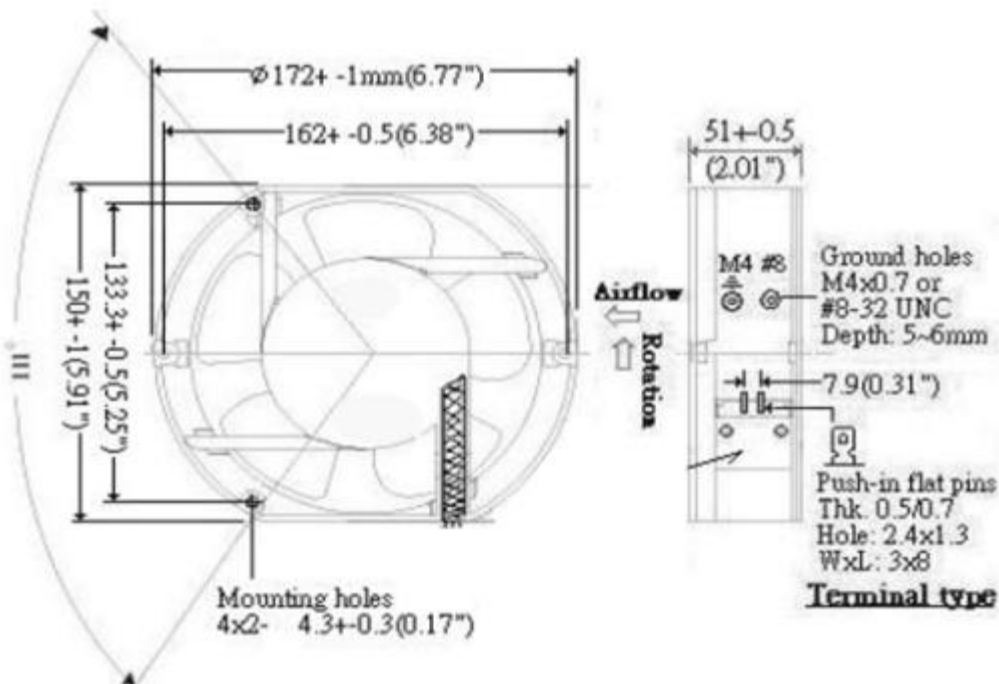



Specifications

- Frame: Die cast Aluminium , Black
- Impeller: PBT , UL94V-0 Thermoplastic

- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-10C ~ +70C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage	Current	Connection Type
6196832	OA172SAP-11-1TB	3500	235	55	115	80~130	31	Terminal
6196898	OA172SAP-22-1TB	3500	235	55	230	160~260	29	Terminal
6196876	OA172SAP-22-1TB(20)* 3	3500	235	55	230	160~260	29	Terminal