


# Deep groove ball bearings, single row, seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
3	10	4	0,54	0,18	0,007	-	40000	0,0015	623-2RS1

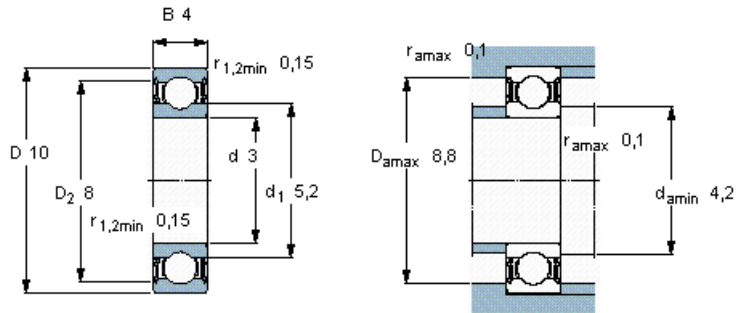

### Calculation factors

$k_r$  0,025  
 $f_0$  7,5