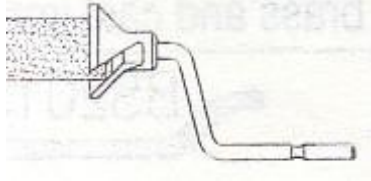


Deburring Blades

EX 2001 External Rotodrive Chamfering Head

RS Stock No. [339-4443](#)

		<p>90° External Rotodrive Chamfer Head Range: 4 – 18mm diameter Blade shank diameter 3.2mm Blade material: HSS M2 Blade hardness: 62-64 HRC Used with NG-1 Handle or S Holder with NG-3 Handle</p>
---	--	--

Packed Weight and Dimensions:

Weight g	W mm	H mm	L mm
20	36	22	70