



75869-106LF - Quickie® : Double Row, 34 Positions, 2.54 mm (0.1 in.), Vertical, Shrouded Header 0.76 µm (30 µin.) Gold or GXT™ Plating

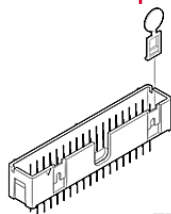

www.fci.com

Mating Half

 71600-634LF

Specifications

Approvals / Certifications	
UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
Mechanical	
Retention force	20N min.
Dimensional	
Length (Tail)	3.05 mm (0.12 in.)
Electrical	
Current rating	3 amp Continuous
Resistance (Insulation)	10000 M-ohms
Voltage rating	500V AC rms
General	
Number of contacts (Total)	34
Number of rows	2
Orientation	Vertical
Attachment type (Board)	Through Mount
Mating half	Quickie® IDC series 71600 and Dubox CTW series 65239 and 65549
Mounting	
Solder process	Wave
Other Features	
Packaging (Type)	Tube
Type	Low Profile
Physical	
Color (Housing)	Blue
Material (Contact)	Phosphor Bronze
Plating (Contact area)	0.76 µm (30 µin.) Gold or 0.76 µm (30 µin.) GXT™
Plating (Tail)	3.81 µm (150 µin.) Tin
Underplating (Contact)	1.27 µm (50 µin.) Nickel
Flammability rating	UL 94V-0
Temperature (Range)	-65°C to +125°C