


Verbatim LED MR16 GU5.3 7W 3000K Warm White 385 LM DIM

- GU5.3 Socket
- 12 V AC/DC Voltage
- 30,000 hours Lifetime
- Dimmable
- 81% Energy Saving
- Equivalent to 37W incandescent bulb

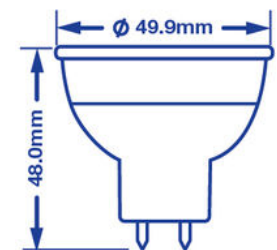


Product Number	52241
General Data	
Lamp Socket	GU5.3
Electric Data	
Wattage (W)	7
Wattage Equivalent (W)	37
Voltage (V)	12 V AC/DC
Dimmable	yes
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	48
Diameter (in mm)	49.9
Weight (g)	46
Photometric Data	
Luminous Flux 90° Cone (lm)	385
CRI	≥ 80
CCT (K)	3000
Luminous Intensity (cd)	700
Beam Angle (°)	40
Luminous Efficacy (lm/W)	55
Lifetime (hrs)	30,000
Switching Cycle	60,000



02/07/2014


Photometric Diagrams

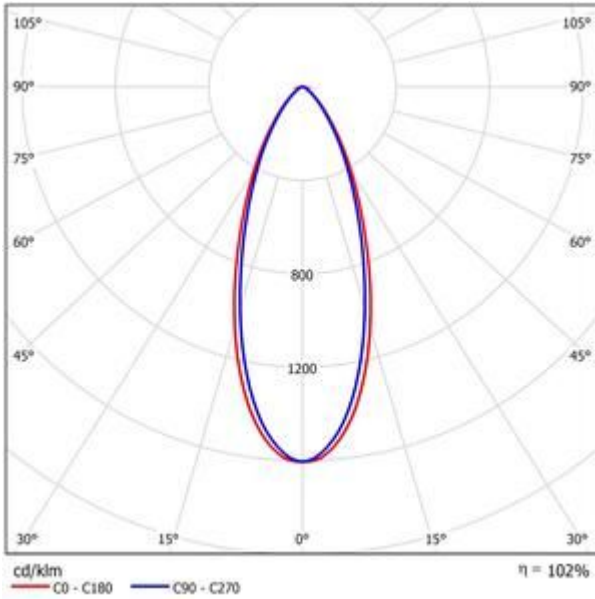

Distance [m]	Cone Diameter [m]	Illuminance [lx]
0.5	0.34 0.37	E(0°) 2788 E(C90) 19.0° 1182 E(C0) 20.5° 1152
1.0	0.69 0.75	E(0°) 697 E(C90) 19.0° 295 E(C0) 20.5° 268
1.5	1.03 1.12	E(0°) 310 E(C90) 19.0° 131 E(C0) 20.5° 128
2.0	1.38 1.50	E(0°) 174 E(C90) 19.0° 74 E(C0) 20.5° 72
2.5	1.72 1.87	E(0°) 112 E(C90) 19.0° 47 E(C0) 20.5° 46
3.0	2.07 2.24	E(0°) 77 E(C90) 19.0° 33 E(C0) 20.5° 32

Distance [m] Cone Diameter [m] Illuminance [lx]
 — C0 - C180 (Half-value Angle: 41.0°)
 — C90 - C270 (Half-value Angle: 38.0°)

Energy Rating

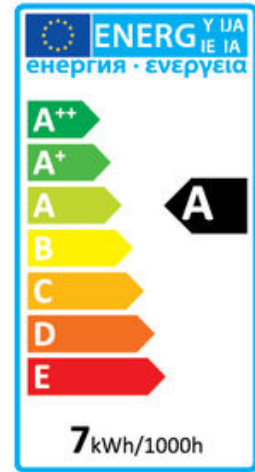

Technical Packaging Details

Barcode

023942522416

EAN 128

(02)00023942522416(37)10(91)162

EAN 14

50023942522411

Pack Dimensions (HxWxL)

H 65 x W 50 x L 50

Pack Weight

59

MOQ

10

Carton Dimensions (HxWxL)

H 58 x W 135 x L 287

Cartons/Pallet

256

Layers/Pallet

16

Units/Pallet

2560

02/07/2014