



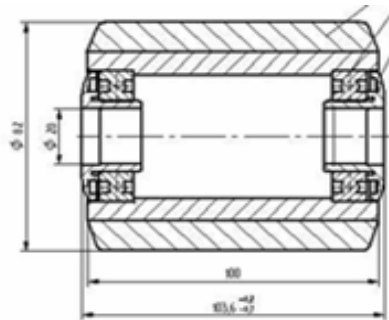

Data-sheet ETX Type F

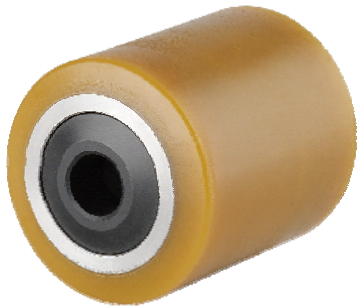

ETX085x85-Ø25 NL90-Type F

EAN4031582339574

Wheel centre made of steel, tread made of Polyurethane, casted, precision ball bearing, sealed

Wheel diameter: 85 mm

Width of Tread: 85 mm

Axle Hole Ø: 25 mm

Hub length: 90 mm

Temperature: - 20 / + 60 °C

Hardness of tread: Shore A 92

Dynamic Load capacity: 800 kg