

HUBER+SUHNER® DATA SHEET


Coaxial Cable Connector: 24_MMCX-50-2-1/111_O



Description

Straight panel bulkhead cable jack, flange mount

Interface standards
SUHNER-MMCX

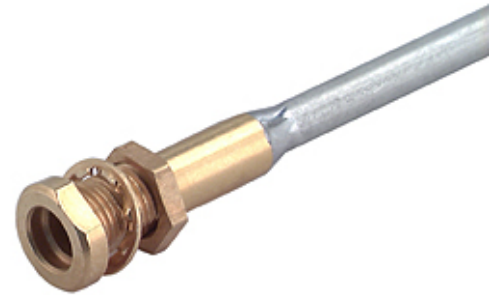

Technical Data

Electrical Data

Impedance 50 Ω
Interface frequency max. 6 GHz

Mechanical Data

Centre contact crimped
Outer contact soldered
Weight 0.0009 kg

Environmental Data

Operating Temperature -55 °C to 155 °C
2002/95/EC (RoHS) compliant

Material Data

Piece Parts

Centre contact	Copper Beryllium Alloy
Outer contact	Brass
Body	Brass
Insulator	PFA / PTFE
Fastening nut	Brass
Washer	Bronze

Surface Plating

Gold Plating (Nickel underplated)
Gold Plating
Gold Plating
Gold Plating
Gold Plating
Gold Plating

Related Documents

Outline drawing	DOU-00009970
Catalogue drawing	DCA-00009291
Assembly instruction	DOC-0000180170
Mounting hole	ML68

Ordering Information

Single package 24_MMCX-50-2-1/111_OE

Additional Information

Suitable cable EZ_86_TP_M17

HUBER+SUHNER is certified according to ISO 9001 and ISO 14001

WAIVER!

It is exclusively in written agreements that we provide our customers with warrants and representations as to the technical contained specifications and/or the fitness for any particular purpose. The facts and figures herein are carefully compiled to the best of our knowledge, but they are intended for general informational purposes only.



HUBER+SUHNER AG
RF Technology
9100 Herisau, Switzerland
Phone +41 (0)71 353 41 11
Fax +41 (0)71 353 45 90
www.hubersuhner.com

HUBER+SUHNER – Excellence in Connectivity Solutions