




ENGLISH

Datasheet

Stock No: 522-614

RS Pro 4 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

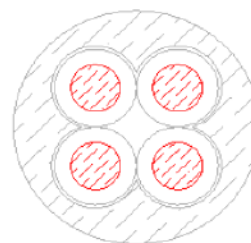

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 24$

Insulation: PVC

Insulation Dia. (mm): $2.34 \pm 0.1 \times 4C$

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 7.05 ± 0.25

Colour:

The colour of the insulation: Black x 3 ,
Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking(3times/m):

RS 522614 YY/NR 4 Core x 0.75mm²

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<28.1

Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 6 A