

## Datasheet

### PVC 5m Long Grey Flexible Ducting Reinforced, 120mm Bend Radius , Applications Various

RS Stock number 413-8963



OREGON LIGHTWEIGHT


Code 355

**Description:** A white PVC helix embedded in flexible dark grey PVC. An extremely flexible all PVC self-extinguishing ducting to UL94 V2.

**Temperature Range:** -10°C +60°C

**Applications:** Suitable for use in applications with confined access. It has good abrasion resistance and is suitable for shot recovery, wood chippings, sawdust and dust and fume extraction. A versatile ducting.

**Advantages:** Smooth bore, corrugated cover - the ducting retains its full diameter even in tight bending radii.

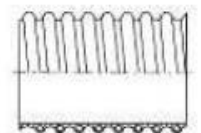

All data refers to performance at 18°C. Any increase of temperature, above or below, will affect the performance data.  
We reserve the right to change all technical data without prior notice.



<b>OREGON LIGHTWEIGHT</b>				
<b>I.D. mm.</b>	<b>Weight gr./mtr.</b>	<b>Bending Radius mm.</b>	<b>Vacuum m.H<sub>2</sub>O</b>	<b>Coil Length mtr.</b>
20	120	20	5	30
25	170	25	5	30
30	200	30	5	30
32	210	32	5	30
35	240	35	5	50
38	260	38	5	50
40	280	40	5	50
45	360	45	4	50
50	430	50	4	50
60	540	60	4	50
63	580	63	4	50
70	650	70	4	50
76	720	76	4	50
80	780	80	4	50
90	850	90	4	50
100	1000	100	4	50
110	1100	110	4	30
120	1200	120	4	30
125	1250	125	4	30
130	1300	130	4	30
140	1500	140	4	30
150	1700	150	3	30
160	1900	160	3	20
180	2200	180	3	20
200	2400	200	3	20
250	3350	250	3	10
300	4100	300	3	10

All data refers to performance at 18°C. Any increase of temperature, above or below, will affect the performance data.

We reserve the right to change all technical data without prior notice.