


Deep groove ball bearings, single row, unsealed

Product information



Tolerances , see also text
Radial internal clearance , see also text
Recommended fits
Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit	Speed ratings		Mass	Designation
d	D	B	dynamic	static	P_u	Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
90	190	43	151	108	3,8	7500	4800	4,90	6318 *

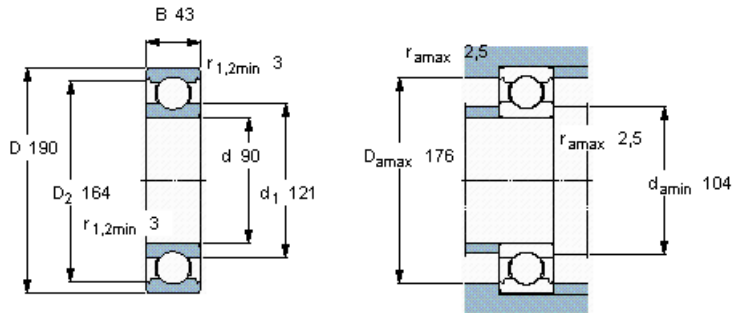

Calculation factors

k_f 0,03
 f_0 13