


ST32 325W SOLDERING IRON

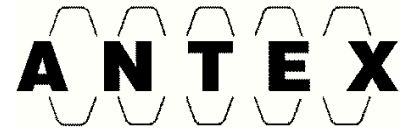


DATA SHEET

769-3123



SPECIFICATIONS ST32 (STRAIGHT) 325WATT SOLDERING IRON

NOMINAL POWER (W)	325
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	500
FITTED BIT (D.F.)	7/8" (22mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with European plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1000
DIMENSIONS (approx.)	A: (bit) 55mm B: (handle & element) 305mm.

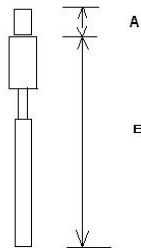

TYPICAL APPLICATIONS:

Used particularly for soldering cans & boxes, transformer casings, heat exchangers & radiators.