


**71600-126LF - Quickie® : Receptacle -Double  
row - 26 Positions - 2.54 mm (0.1 in.)**

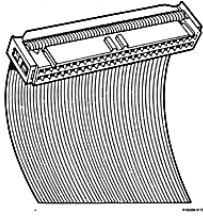

[www.fci.com](http://www.fci.com)

### Mating Half

71918-226LF

71922-226LF

### Specifications

#### Approvals / Certifications

UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved

#### Electrical

Current rating	1 amp Continuous
Resistance (Contact)	15 m ohms max.
Resistance (Insulation)	50000 M-ohms
Voltage rating	1000V AC rms

#### General

Insulation Displacement Contact (IDC)	IDC Receptacle
Number of contacts (Total)	26
Number of rows	2
Polarization	Center and Dual
Strain Relief	None
Style	Standard Single Beam
Termination Style	IDC
Application Equipment	QP-104 QP-112 QP-106
Mating half	Mates with shrouded Eject Latch Header Latch 2

#### Other Features

Packaging (Type)	Tube
------------------	------

#### Physical

Color (Housing)	Grey
Material (Contact)	Phosphor Bronze
Material (Housing)	Glass - Filled Thermoplastic Polyester
Plating (Contact area)	0.76 $\mu\text{m}$ (30 $\mu\text{in.}$ ) Gold
Underplating (Contact)	1.27 $\mu\text{m}$ (50 $\mu\text{in.}$ ) Nickel
Flammability rating	UL 94 V-0
Temperature (Range)	-65°C to +105°C