



Datasheet



ENGLISH

Embedded Linear Power Supply Encapsulated, 240V ac Input, 48V dc Output, 6A, 288W

RS Stock 597-598



Dimensions (mm)

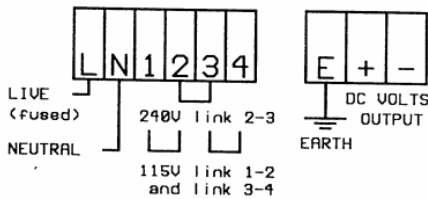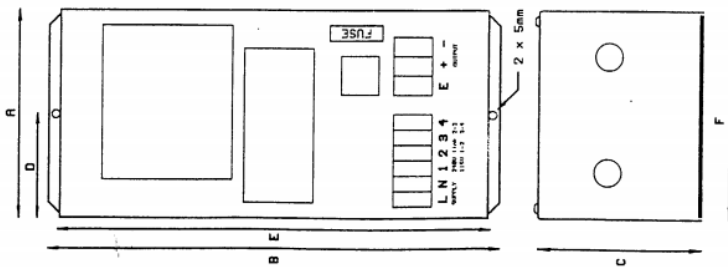

Specification

INPUT: 110/120 or 220/240 Vac
 50/60 Hz Link selectable
 Supplied set at 220/240

| OUTPUT: | V dc | A dc | Fuse |
|---------|------|------|------|
| PS1206 | 12 | 6 | 7.5 |
| PS1212 | 12 | 12 | 15 |
| PS2406 | 24 | 6 | 7.5 |
| PS2412 | 24 | 12* | 15 |
| PS4806 | 48 | 6 | 7.5 |

* Derated to 10A after 1hr

Output fuse 1.25 x 0.25 QB

REGULATION: 20% typ

RIPPLE: 5% typ

TEMPERATURE: 0 to + 40C

Note: mains supply must be fused