


# Datasheet

## AC Axial Fan, 172 Dia. x 51mm, 399m<sup>3</sup>/h, 35W, 230 V ac (OA172S Series)

RS Stock 619-6882



### Dimensions: (mm)

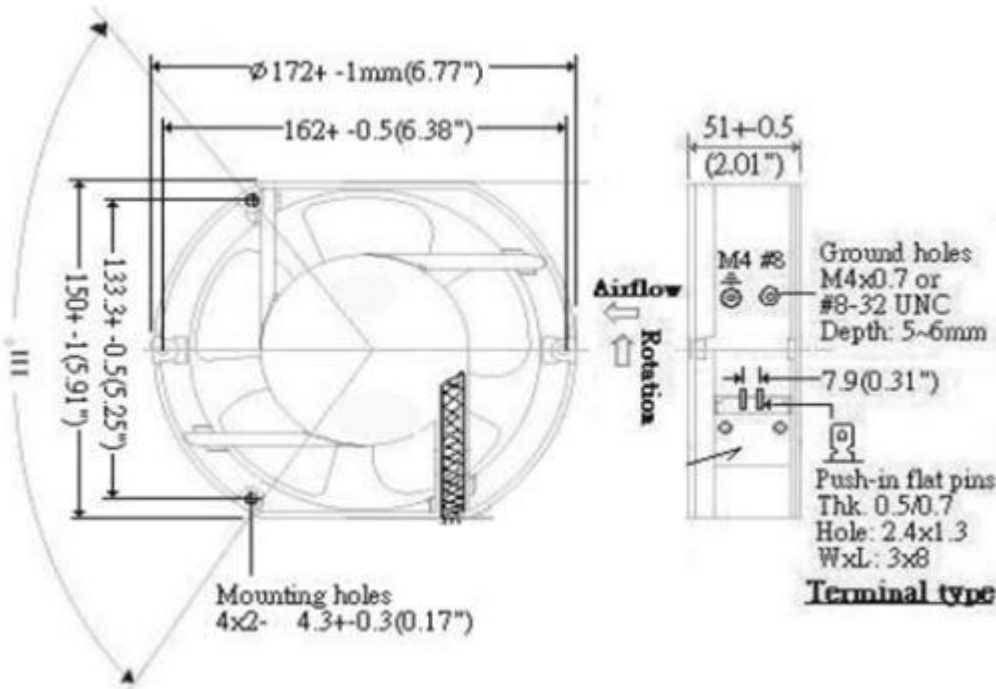



### Specifications

- Frame: Die cast Aluminium , Black
- Impeller: PBT , UL94V-0 Thermoplastic
  
- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-10C ~ +70C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage Range	Watts	Connection Type
6196854	OA172SAP-11-1TB	3300	300	61	120	80~130	50	Terminal
6196882	OA172SAP-22-1TB	3300	300	61	230	160~260	50	Terminal