


Data Sheet

2 core unscreened cable,7x0.1mm 25m

Cross Section:

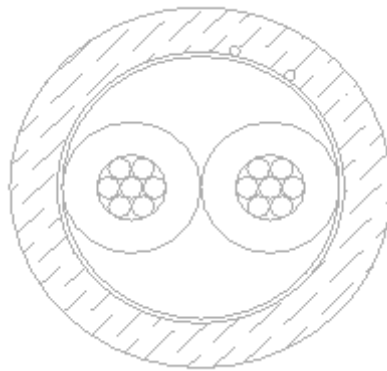

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V):250

Flammability Test: IEC60332-1

Standard:

Manufacture to Def. Stan 61.12 Part 4 & 5

Construction:

Conductor:Tinned Copper

Conductor Dia. (mm): 0.10±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 0.7±0.05 x 2C

Tape: Mylar Spiral

Coverage: ≥115%

ID Thread: Green, White/Green

A rip cord : 210 D

Jacket: FR-PVC

Outer Dia. (mm): 2.3±0.1



Colour:

The color of the insulation: Red , Blue

The jacket color: Black

Marking(3times/m):

RS 6603967 7 - 1 - 2A

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<384

Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>200

Current Rating : 0.25 A

