


## 34 - Inch 15° and 75° hinged "midget" open end wrenches | 34.1/4

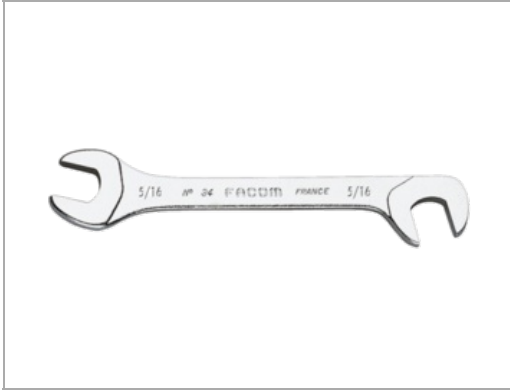

### Description

- "Midget" open end wrenches: short shank and slim heads for manoeuvrability in confined spaces.
- Heads hinged at 15° and 75° allow to intervene on nuts inaccessible with a standard wrench.
- Dimensions in inches: from 3/16" to 11/16".
- Presentation: satin chrome finish.

### Specifications

[g]	15
L [mm]	80
A ["]	1/4
E [mm]	2,7
B [mm]	15
E maxi [mm]	2,7
Width I [mm]	80

