

ToLEDo GLS

ToLEDo GLS 10W 806LM 827 E27 SL

0026388



Range features

- Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps
- Over 80% energy saving compared to incandescent - Rapid payback on investment
- Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels
- Instant start - ideal for use on presence detection and in high use areas



PRODUCT OVERVIEW

| | |
|----------------------------|---------------|
| Light colour | Homelight |
| Technology | LED |
| Ordering number | 0026388 |
| Average life (Rated) (h) | 15000 |
| Energy class | A+ |
| Lamp shape | A60 |
| Lamp finish | Frosted |
| Dimmable | No |
| Cap/Base | E27 |
| Type | ToLEDo GLS |
| EAN code | 5410288263885 |
| CRI (Ra) | 80 |
| Colour temperature (K) | 2700 |
| Luminous flux (Rated) (lm) | 806 |
| Watt (Nominal) (W) | 10 |
| Equivalent watt (W) | 60 |
| Voltage (V) | 220-240 |

ToLEDo GLS

ToLEDo GLS 10W 806LM 827 E27 SL

0026388

DATA TABLE

General data

| | |
|--------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Dry applications use only | Yes |
| Ordering number | 0026388 |
| Technology | LED |
| Energy saving lamp | Yes |
| Average life (Nominal) (h) | 15000 |
| Average life (Rated) (h) | 15000 |
| Energy class | A+ |
| Lamp finish | Frosted |
| Lamp shape | A60 |
| Dimmable | No |
| Cap/Base | E27 |
| Type | ToLEDo GLS |
| EAN code | 5410288263885 |
| Long description | Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps. Over 80% energy saving compared to incandescent - Rapid payback on investment. Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels. Instant start - ideal for use on presence detection and in high use areas |
| Product name | ToLEDo GLS 10W 806LM 827 E27 SL |
| Lamp mercury content (mg) | 0 |
| Starting time (max) (s) | 0.05 |
| Warm-up time to 60% of full light (max) (s) | < 1s => 60% |
| Control gear required | No |
| Intended purpose | No |
| No. of switching cycles before premature failure (min) | 20,000 |
| Special purpose lamp | No |
| Sales pack quantity | 6 |
| Optimal operating condition (°C) | 25 |

Optical data

| | |
|----------------------------------------------|-----------|
| Light colour | Homelight |
| CRI (Ra) | 80 |
| Colour temperature (K) | 2700 |
| Luminous flux (Rated) (lm) | 806 |
| Lumen maintenance at end of nominal life (%) | 70 |
| Luminous flux (Nominal) (lm) | 806 |

ToLEDo GLS

ToLEDo GLS 10W 806LM 827 E27 SL

0026388

Electrical data

| | |
|----------------------------------------|---------|
| kWh per 1000 hours burning time | 10 |
| Watt (Rated) (W) | 10 |
| Watt (Nominal) (W) | 10 |
| Equivalent watt (W) | 60 |
| Voltage (V) | 220-240 |
| Lamp power factor | 0.7 |

Physical data


| | |
|---------------------------------------------------|-----------------------|
| Weight (kg) | 0.11 |
| Lamp Length (mm) - C/L | 110 |
| Max. Lamp Diameter (mm) - D | 60 |
| Single packaging type | Box/Sleeve |
| Single package dimensions (L x W x H) (cm) | 11.40 x 6.40 x 6.40 |
| Inner package dimensions (L x W x H) (cm) | 20.90 x 14.10 x 14.10 |
| Inner package net weight (kg) | 0.63 |
| Outer package dimensions (L x W x H) (cm) | 74.80 x 21.70 x 31.80 |

ToLEDo GLS

ToLEDo GLS 10W 806LM 827 E27 SL

0026388

TECHNICAL DRAWINGS

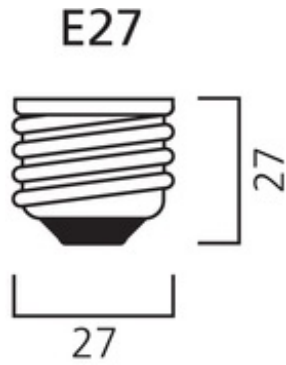

ENERGY LABEL

