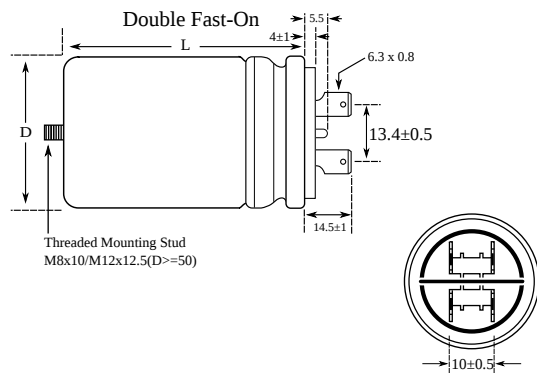


C87, Film, Film/Foil Polypropylene, Motor Run, 55 uF, 5%, 470 VAC

**Dimensions**

D	50mm +1mm
L	133mm +/-2mm

Packaging Specifications

Mounting:	Bolt - M12x12.5
Packaging:	Bulk, Bag

General Information

Supplier:	KEMET
Series:	C87
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Aluminum Case, Plastic Cover, Spun Seal
Features:	Spun Seal, Safety Class S2, UL_94 V0 Disk
RoHS:	Yes
Lead:	Fast On (2+2)
Qualifications:	UL, VDE, CQC, CSA (600VAC), UL_94 V0 Disk

Specifications

Capacitance:	55 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85°C
Max dV/dt:	20 V/us